



Part Number:

254-PB514-ROX

DIMENSIONS: mm (in.)

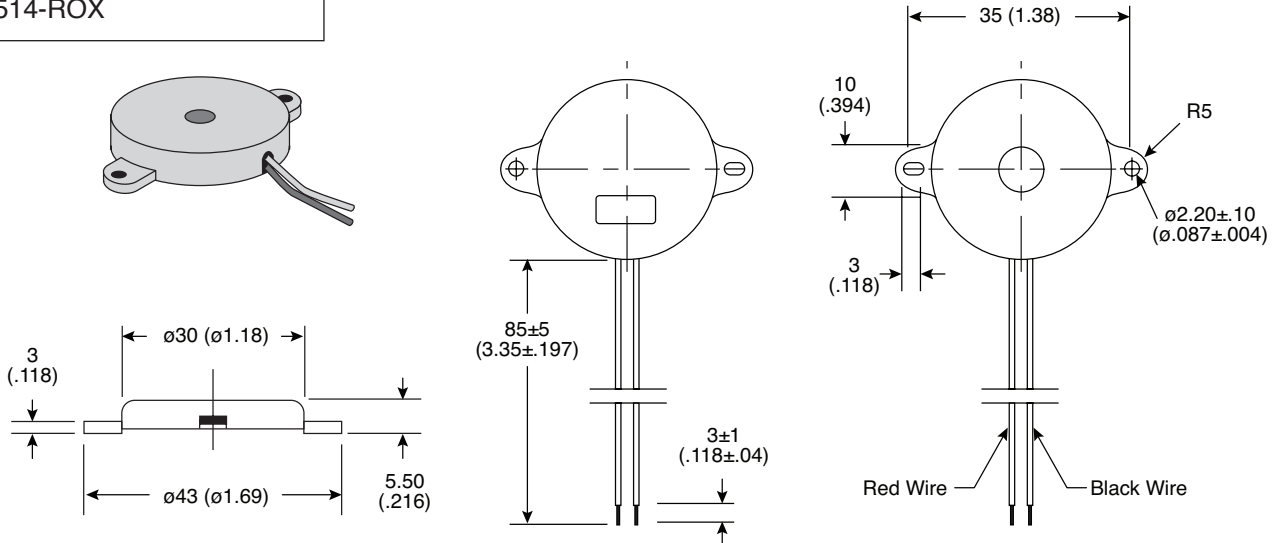

**Piezoelectric Buzzer
(External Drive)**

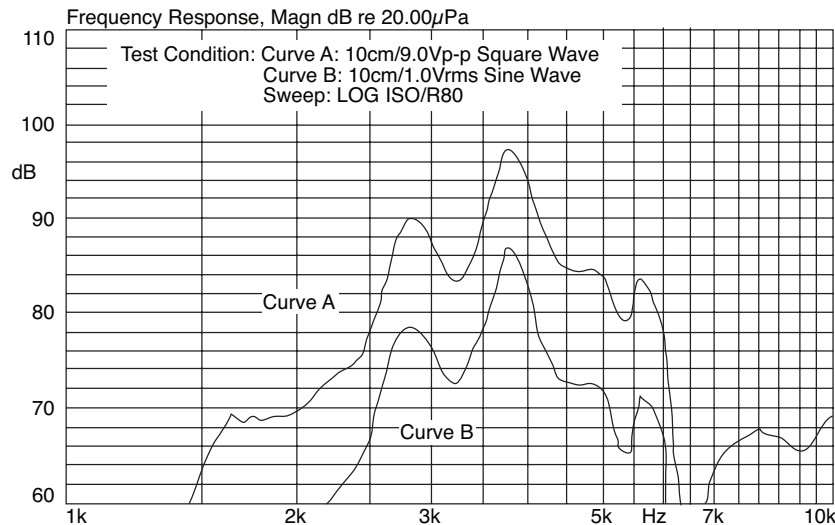

KT-400408

Electrical Specifications:

- Sound Pressure Level:
85dB min. at 3.5KHz/9Vp-p Square Wave/10cm.
75dB min. at 3.5KHz/1Vrms Sine Wave/10cm.
- Capacitance: 24,000pF ± 30% at 120Hz
- Current Consumption: 4mA max. at 3.5KHz/9Vp-p Square Wave
- Allowable Input Voltage: 30Vp-p max.

Note:

- RoHS compliant by exemption

Mechanical Specifications:

- Operating Temperature: -20°C to +60°C
- Storage Temperature: -30°C to +70°C

Materials:

- Case: ABS
- Lead Wire: 28AWG
- Weight: 4.3 grams

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-PB514-ROX](#)