
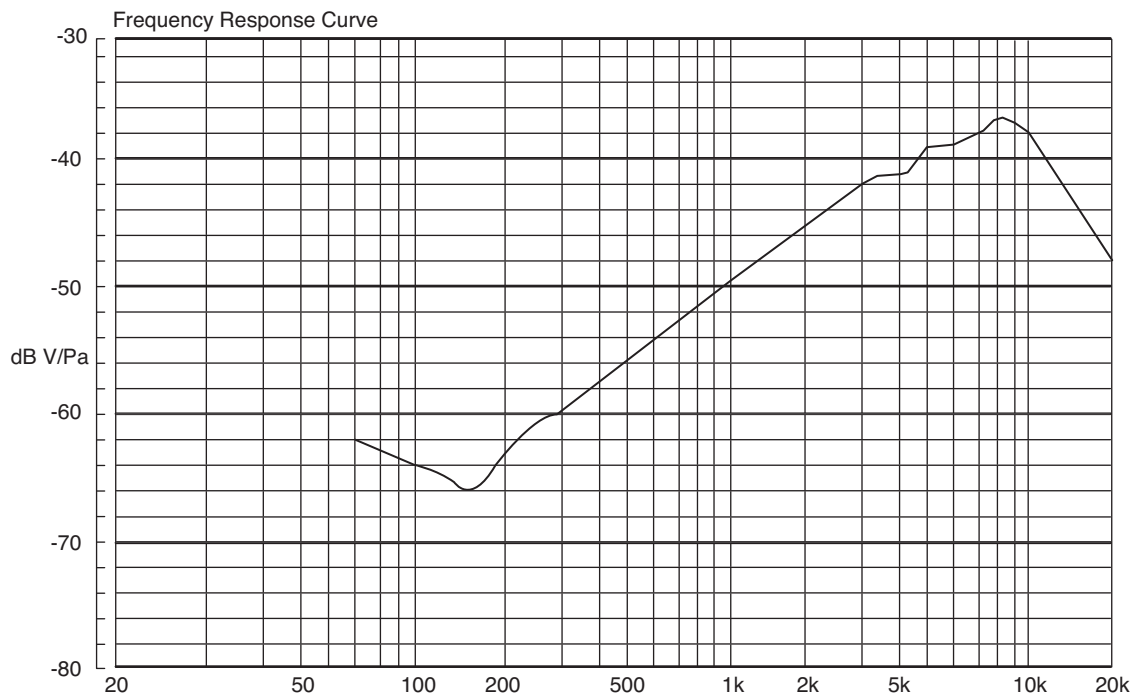


Part Number:

254-ECM605-RO

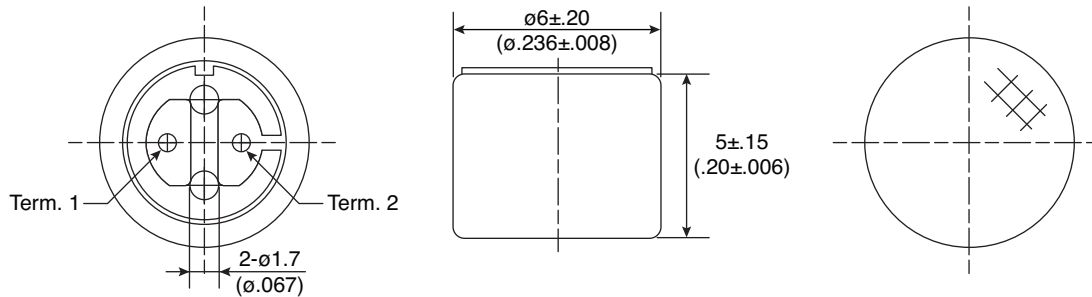

KT-400428

Electrical Specifications:

- Sensitivity: $-50 \pm 3\text{dB}$
- Output Impedance: $2.2\text{K } \Omega$
- Frequency Range: 70-20K Hz
- Standard Operation Voltage: 2.0V
- Current Consumption: 0.5mA (max.)
- S/N Ratio: $> 58\text{dB}$

Mechanical Specifications:

- Operating Temperature: $-25^{\circ}\text{C} \sim +70^{\circ}\text{C}$
- Storage Temperature: $-40^{\circ}\text{C} \sim +70^{\circ}\text{C}$

Note:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-ECM605-RO](#)