

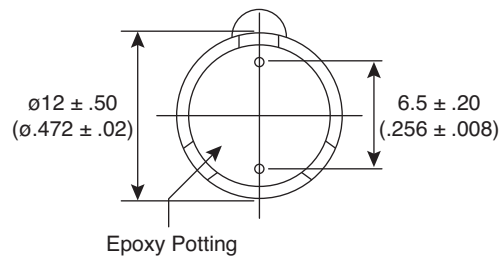
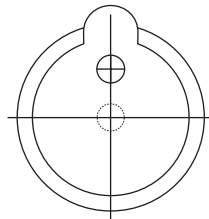
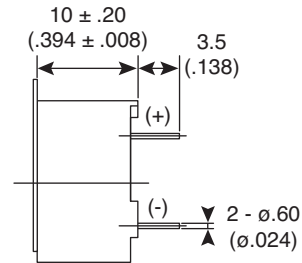


Part Number:

254-EMB1212-RO

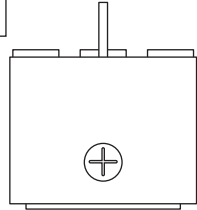

Magnetic Buzzer

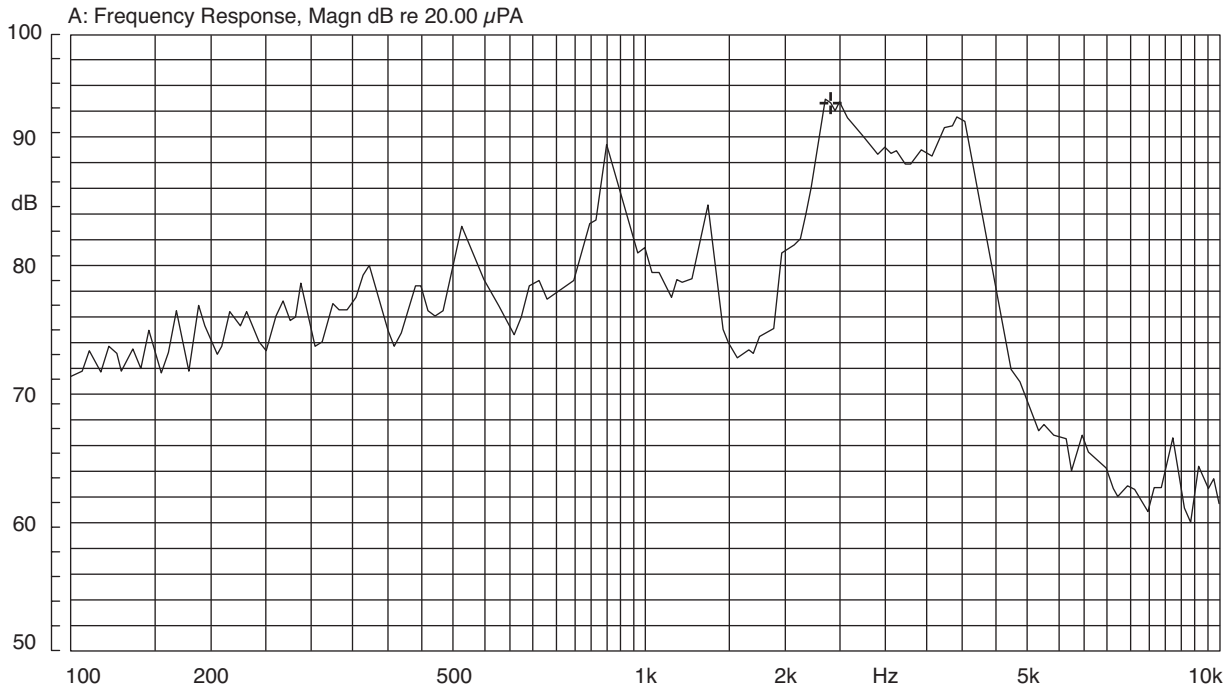

**Electrical Specifications:**

- Rated Voltage: 12 Vo-p
- Operating Voltage: 6~16 Vo-p
- Consumption Current:
  - Mean: 80 mA (max.)
  - Peak: 240 mA (max.)
- Sound Output: 85 dBA (min.)
- Rated Frequency: 2400Hz
- Direct Current Resistance: 140 $\Omega$ ±21

**Mechanical Specifications:**

- Operating Temperature: -30°C~+75°C
- Storage Temperature: -40°C~+85°C

**Note:**

- RoHS Compliant

KT-400463

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-EMB1212-RO](#)