
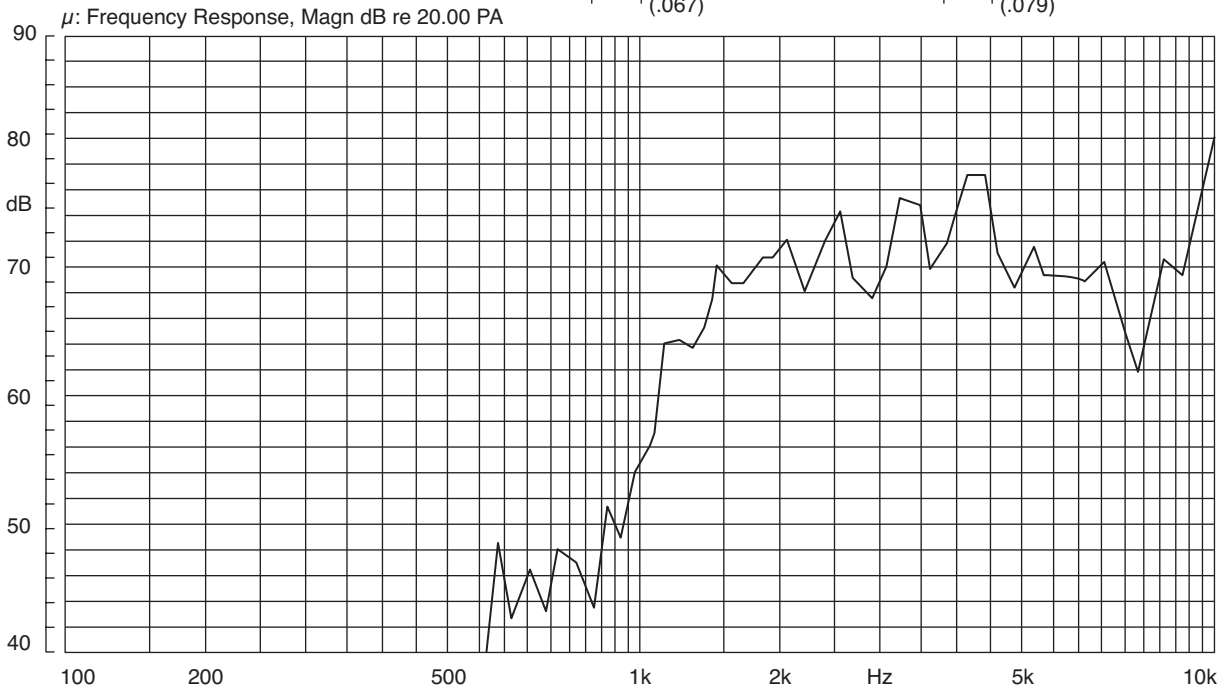


**Part Number:**

254-PB119-ROX

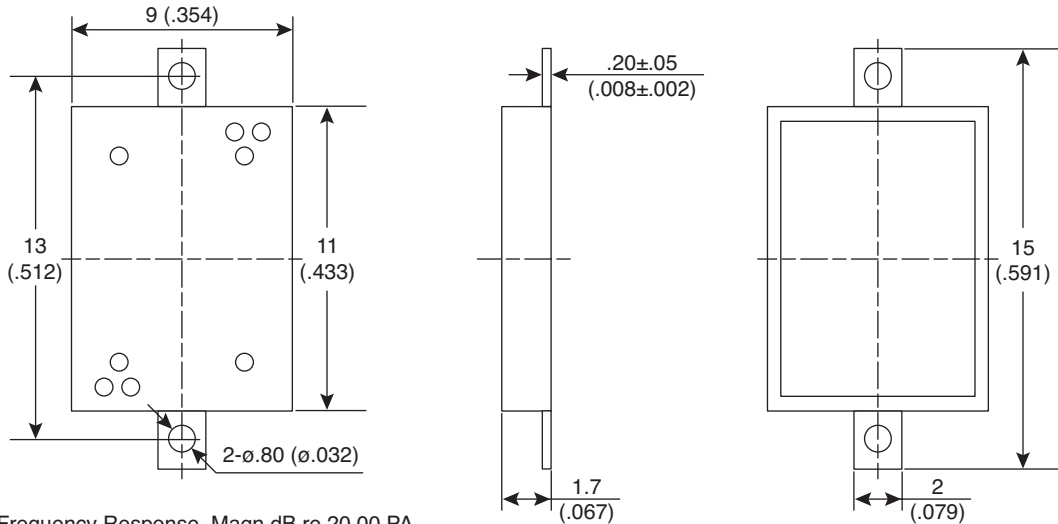

Piezoelectric Buzzer

KT-400474

**Electrical Specifications:**

- Rated Voltage: 5 Vp-p
- Operating Voltage: 1~25 Vp-p
- Rated Current: 5mA (max.)
- Sound Output at 10cm: 70dBA (min.)
- Resonant Frequency: 4100Hz
- Capacitance: 13000pf  $\pm$  30%

**Mechanical Specifications:**

- Operating Temperature: -20°C ~ +70°C
- Storage Temperature: -40°C ~ +85°C

**Note:**

- RoHS Compliant by Exemption

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-PB119-ROX](#)