
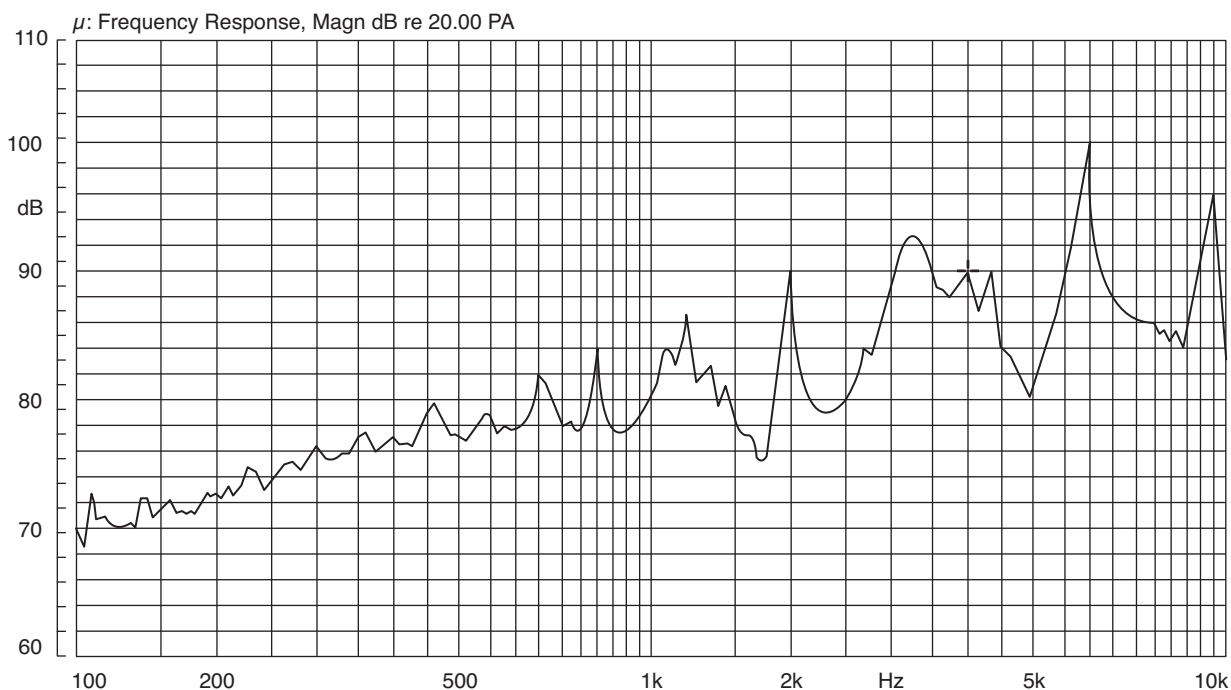


Part Number:

254-PB2240-ROX

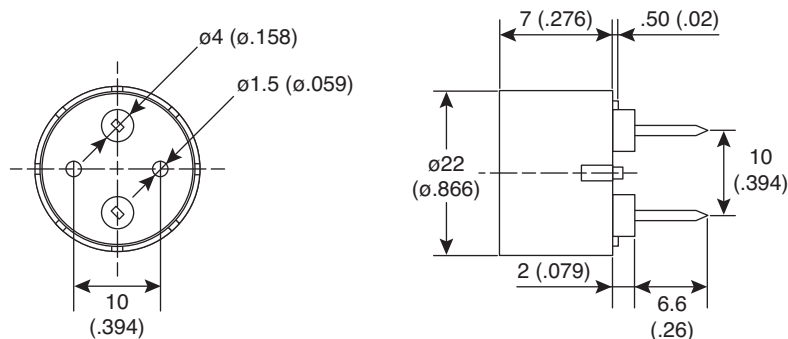

KT-400480

Electrical Specifications:

- Rated Voltage: 9 Vp-p
- Operating Voltage: 1~30 Vp-p
- Rated Current (max.): 7mA
- Min. Sound Output: 85dBA
- Resonant Frequency: 4000Hz ± 500
- Capacitance at 120Hz: 15000pf ± 30%

Mechanical Specifications:

- Operating Temperature: -30°C ~ +75°C
- Storage Temperature: -40°C ~ +85°C

Note:

- RoHS Compliant by Exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-PB2240-ROX](#)