


Cable Assemblies 3.5mm

172-7434-E

KOBICONN

Cable Assemblies 3.5mm

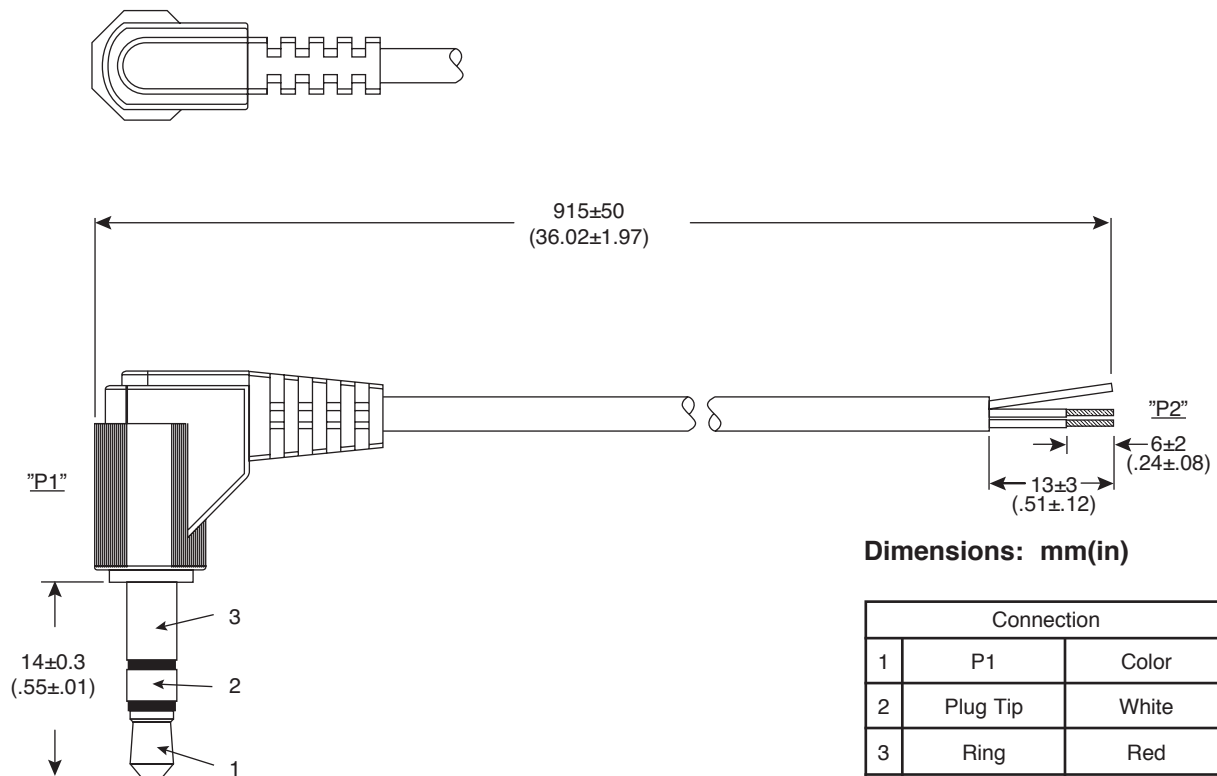

Dimensions: mm(in)

Connection		
1	P1	Color
2	Plug Tip	White
3	Ring	Red
4	Sleeve	Drain

MECHANICAL SPECIFICATIONS

Tensile Strength	Pin plug overmold to cable jacket shall withstand 3kgf pull min. for one min.
-------------------------	---

RoHS Compliant

ELECTRICAL SPECIFICATIONS

Operation Temp	-10°C+80°C
Insulation Resistance	DC/250V 10MΩ Min.
Withstand Voltage	AC/250V 5mA, for one min.

RoHS Compliant

Date Last Revised: 09/12/14

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301289

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7434-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-7434-E](#)