


Dimensions: mm (In.)

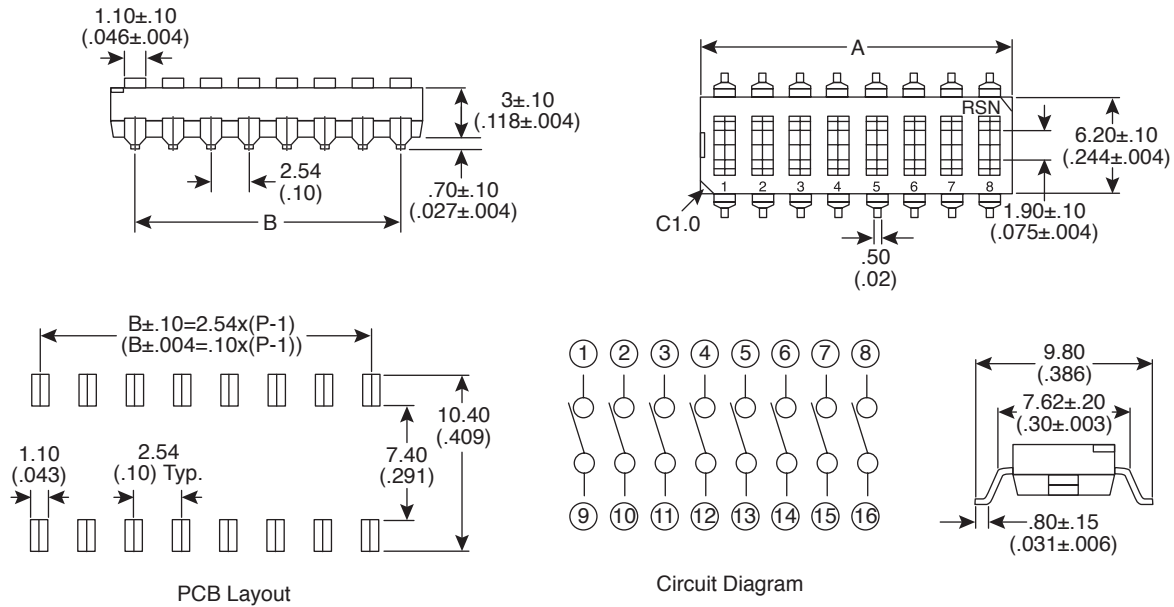

Mechanical Specifications:

- Type: SPST
- Operating temperature: -25°C to +70°C
- Storage temperature: -40°C to +85°C
- Operation force: 600gf max.
- Operating life: 2,000 operations

Electrical Specifications:

- Rating: Switching 25mA/ 24VDC; Non-switching 100mA/ 50VDC
- Contact resistance: 50mΩ max. (initial); 100mΩ max. (after life test)

Note:

- RoHS Compliant and are also process compatible with 260° solder.

Mouser Stock No.	No. of Positions	Dimension "A" (In.)	Dimension "B" (In.)
106-1242-EV	2	.237	.10
106-1244-EV	4	.437	.30
106-1248-EV	8	.837	.70

Surface Mount DIP Switches
 106-1242-EV, 106-1244-EV, 106-1248-EV



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[106-1242-EV](#) [106-1244-EV](#) [106-1248-EV](#)