
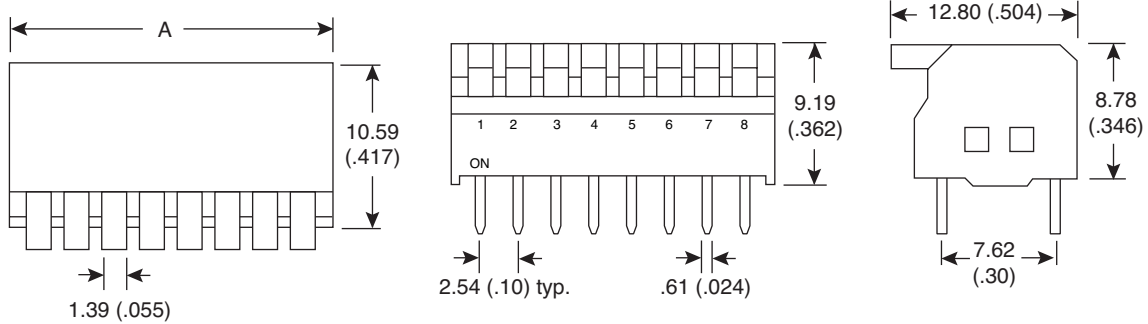


Dimensions: mm (In.)

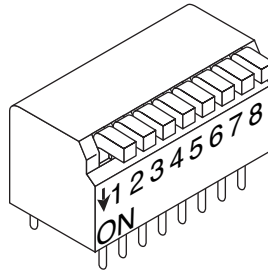

Mouser Stock No.	Position	Dimension "A" (In.)
106-1234-EV	4	.446
106-1238-EV	8	.846

**Mechanical Specifications:**

- Mechanical life: 5,000 operation min.
- Operation force: 400g ±200g
- Type: SPST

**Note:**

- RoHS Compliant and Process Compatible with 260° solder

**Electrical Specifications:**

- Electrical life: 2,000 operation min.
- Rating: Non-switching: 100mA / 50VDC  
Switching: 25mA / 24VDC

**Side Actuated DIP Switches**

106-1234-EV, 106-1238-EV



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[106-1234-EV](#) [106-1238-EV](#)