
 


Dimensions: mm (in.)

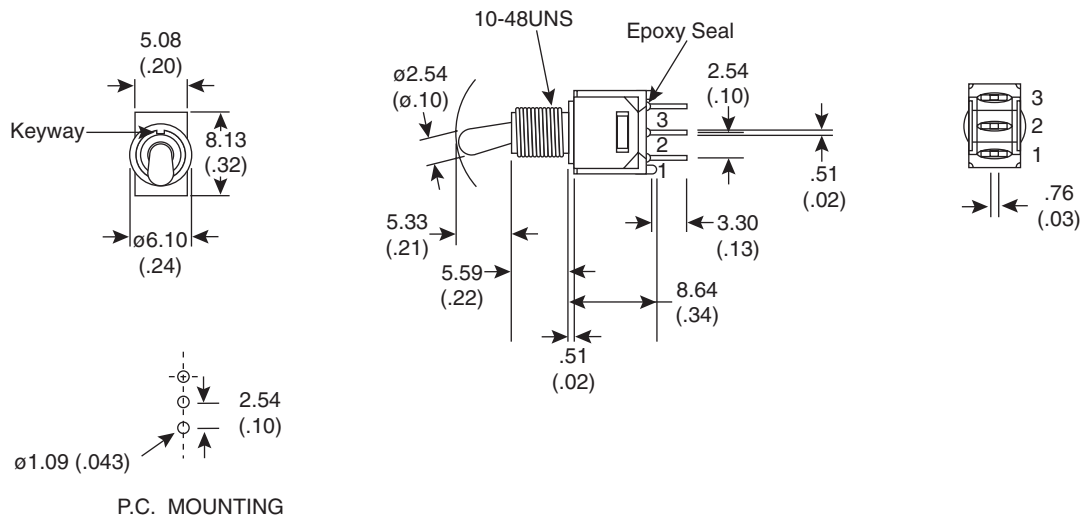

POS.1	POS.2
ON	ON
2-3	2-1



Electrical Specifications:

- Contact Resistance: 20mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@ sea level.
- Rating:
 - 1A/250 VAC
 - 3A/120 VAC or 28 VDC

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Switch Support: Brass, Tin plated.
- Terminal/Contact: Brass, silver plated

Mechanical Specifications:

- Operating Temperature: -30° C to +85° C.

Note:

- RoHS compliant by exemption

Toggle Switch
108-2MS1T2B3M2QE-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-2MS1T2B3M2QE-EVX](#)