



Dimensions: mm (in.)

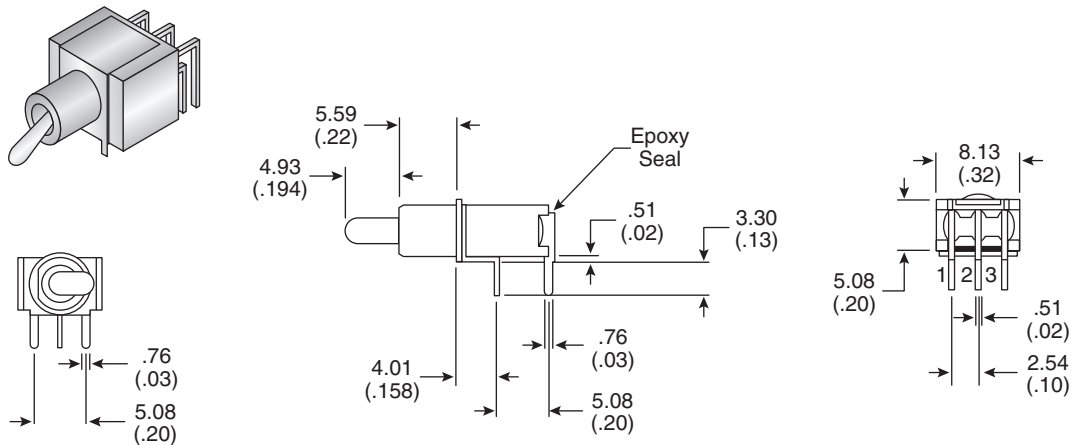


Switch Function

POS.1	POS.2
ON	ON
2-3	2-1

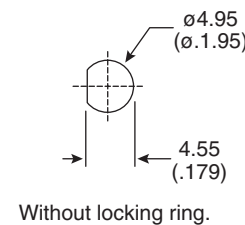

Without locking ring.  
Panel Mounting

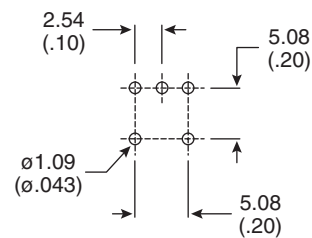

P.C. Mounting

Electrical Specifications:

- Contact Resistance: 20m $\Omega$  max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M $\Omega$  min.
- Dielectric Strength: 1,000 V RMS@ sea level.
- Rating:
  - 1A/250 VAC
  - 3A/120 VAC or 28 VDC

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminals/Contact: Brass, with silver plate
- Switch Support: Brass, Tin plated.

Mechanical Specifications:

- Operating Temperature: -30° C to +85° C.

Note:

- RoHS compliant by exemption.

**Toggle Switch**  
108-2MS1T2B2M6QE-EVX



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-2MS1T2B2M6QE-EVX](#)