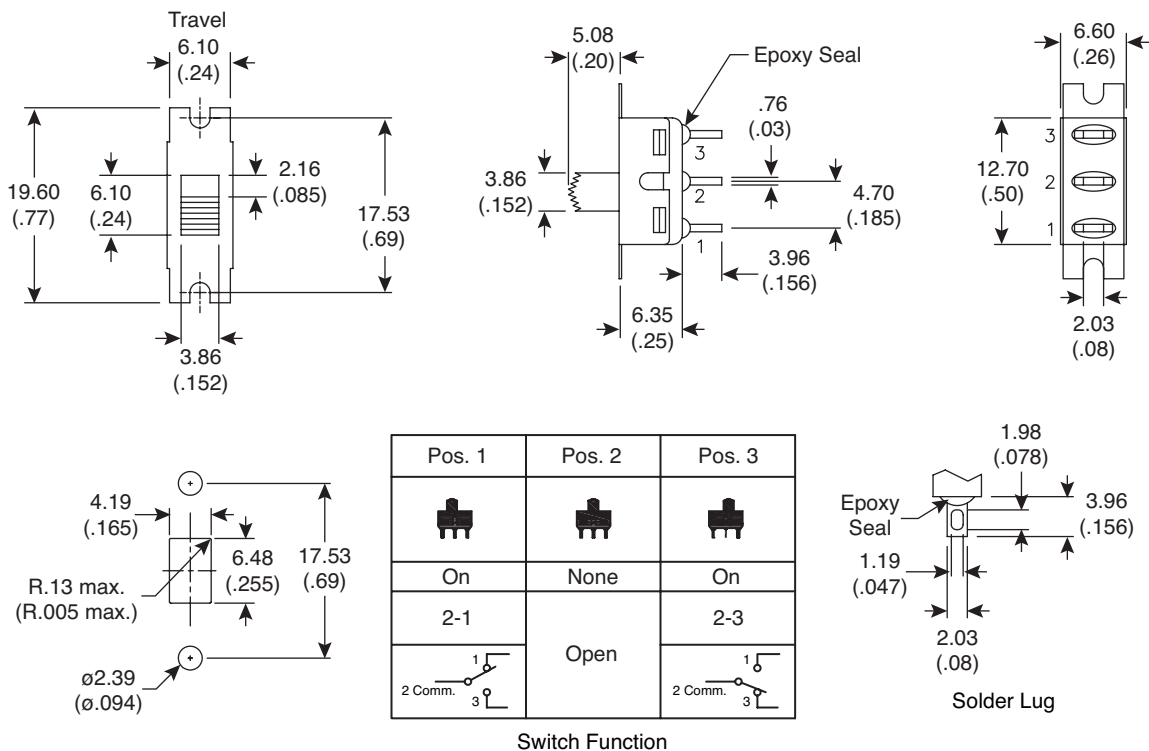


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 2A/ 250VAC, 5A/120VAC
- Contact Resistance: 10m Ω max. initial @ 2-4 VDC 100mA
- Insulation Resistance: 1000M Ω min.
- Dielectric Strength: 1000 V RMS @ sea level

Mechanical Specifications:

- Operating Temperature: -30°C to 85°C
- Mechanical Life: 30,000 make-and-break cycles

Materials:

- Case: Dially phthalate (DAP)
- Actuator: Nylon, black std.
- Housing: Stainless
- Contact: Silver plated
- Terminals: Silver plated copper alloy

Note:

- RoHS Compliant

Slide Switch
103-5006-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-5006-EV](#) [103-5006-EVX](#)