


Dimensions: mm (In.)

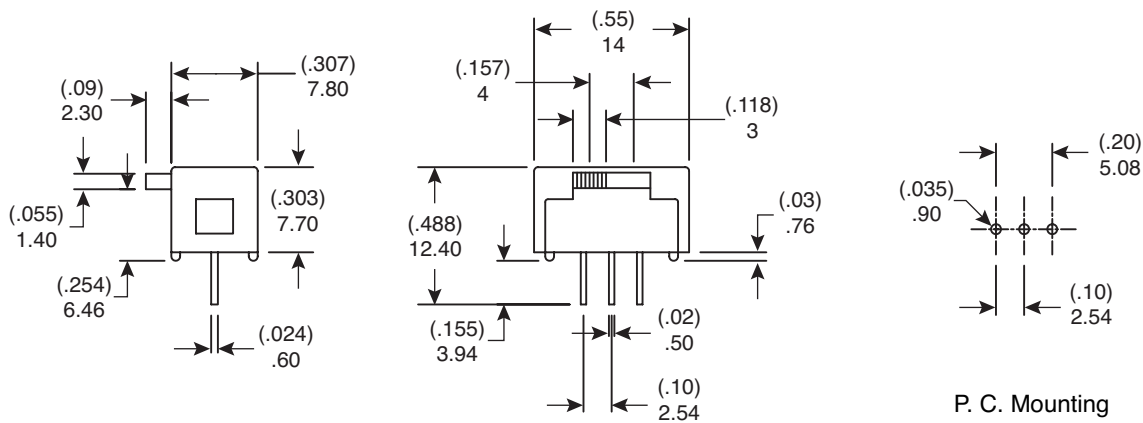

POS.1	POS.2	POS.3
ON	NONE	ON
2-1	OPEN	2-3

Switch Function

Electrical Specifications:

- Rating: 1A/ 250VAC
3A/ 120VAC or 28 VDC
- Contact Resistance: 50mΩ max. initial
- Insulation Resistance: 1000MΩ min.
- Dielectric Strength: 1000 V RMS @ sea level
- Breaking Capacity: 1A 250VAC
- Minimum Load: 100mA

Mechanical Specifications:

- Mechanical Life: 20,000 cycles
- Operating Temperature: -30°C to 85°C

Note:

- RoHS Compliant

Materials:

- Case: Nylon, white
- Actuator: Nylon, black
- Housing: Nylon, black
- Contact: Silver plated copper alloy
- Terminals: Silver plated copper alloy

Miniature Slide Switch
103-5003-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-5003-EV](#) [103-5003-EVX](#)