



Dimensions: mm (In.)

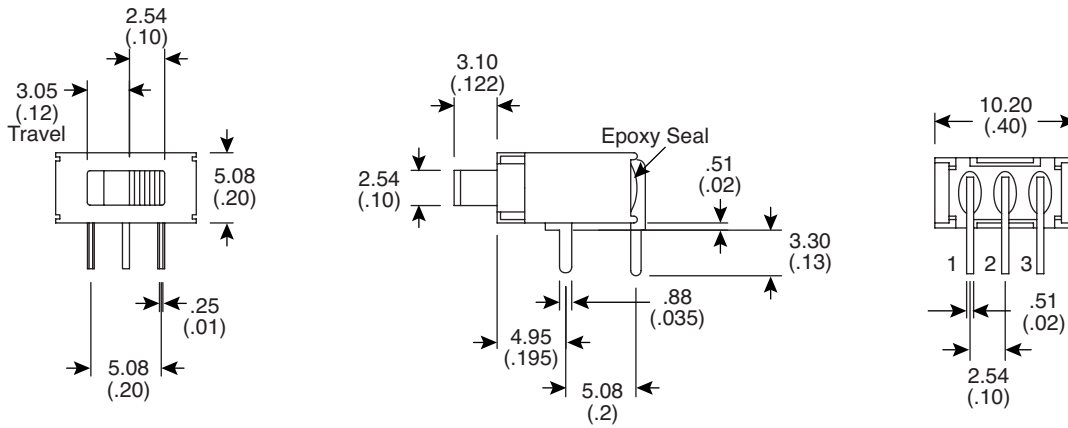

POS.1	POS.2	POS.3
ON	NONE	ON
2-1	OPEN	2-3

Switch Function

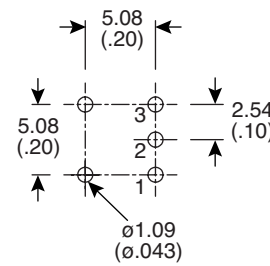

P. C. Mounting

Electrical Specifications:

- Rating: 1A/250VAC
3A/120VAC or 28 VDC
- Contact Resistance: 20mΩ max. initial @ 2-4 VDC
100mA
- Insulation Resistance: 1000MΩ min.
- Dielectric Strength: 1000 V RMS @ sea level

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Note:

- RoHS compliant

Materials:

- Case: Dially phthalate (DAP)
- Actuator: Nylon, black std.
- Housing: Brass, tin plated
- Contact: Silver plated
- Terminals: Silver plated copper alloy

Sub-Miniature Slide Switch

103-5001-EV



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-5001-EVX](#) [103-5001-EV](#)