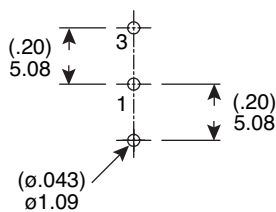
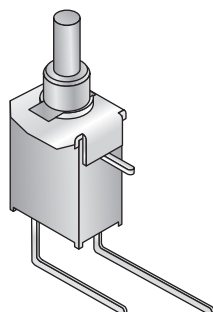


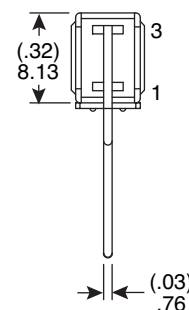
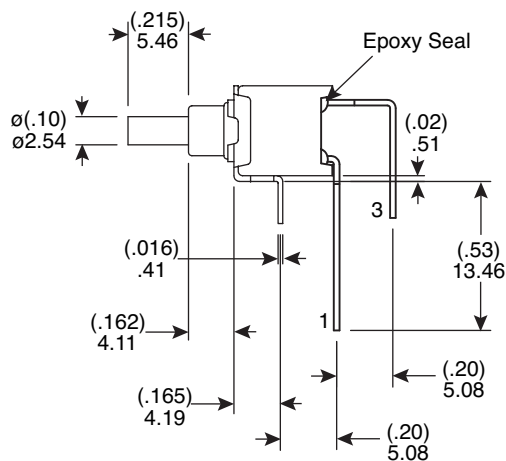
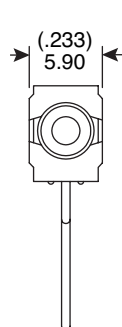
Dimensions: mm (In.)



P.C. MOUNTING

POS. 1	POS. 2
OFF	MOM
OPEN	1-3

SWITCH FUNCTION

**Electrical Specifications:**

- Rating: 0.4 Volt-Amps (VA) max. @20V max. (AC or DC)
- Contact Resistance: 20mΩmax. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩmin.
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Mechanical Life: 50,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Materials:

- Case and Bushing: Glass filled Nylon 6/6, flame retardant, heat stabilized
- Plunger: Thenoplastic Polyester, with internal O-ring seal
- Switch Support: Brass or Steel electronitin plated
- Contact: Gold plated copper alloy

Note:

- RoHS Compliant by Exemption

Sealed Sub-Minature Pushbutton Switch**107-3014-EVX**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[107-3014-EVX](#)