



DIMENSIONS: mm (in.)

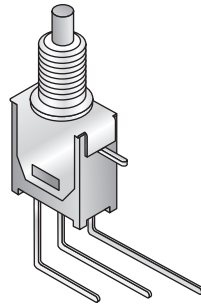

POS. 1	POS. 2
ON	MOM
1-3, 4-6	1-2, 4-5

SWITCH FUNCTION

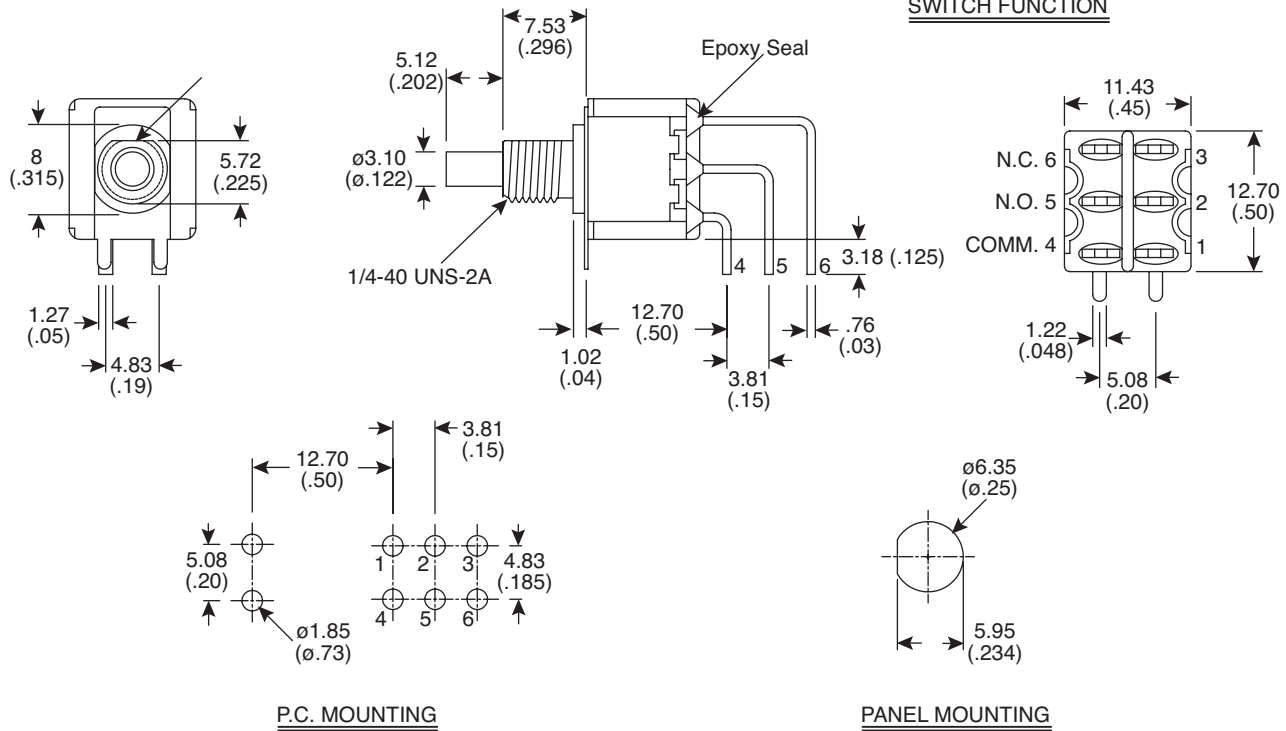

P.C. MOUNTING

PANEL MOUNTING

Electrical Specifications:

- Rating: 1A, 250VAC; 3A, 120VAC or 28 VDC
- Contact Resistance: 20mΩmax. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩmin.
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Mechanical Life: 50,000 make-and-break cycles.
- Operating Temperature: -30°C to 85°C

Materials:

- Case: Diallyl phthalate (DAP)
- Plunger: Glass filled nylon or glass filled polyester
- Bushing: Brass, nickel plated.
- Housing: Stainless steel
- Contact: Silver plated.

Note:

- RoHS compliant by exemption

Snap-Acting Pushbutton Switch
107-3010-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[107-3010-EVX](#)