



Dimensions: mm (In.)

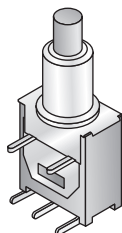

| POS. 1 | POS. 2 |
|--------|--------|
| | |
| ON | MOM |
| 2-1 | 2-3 |
| | |

SWITCH FUNCTION

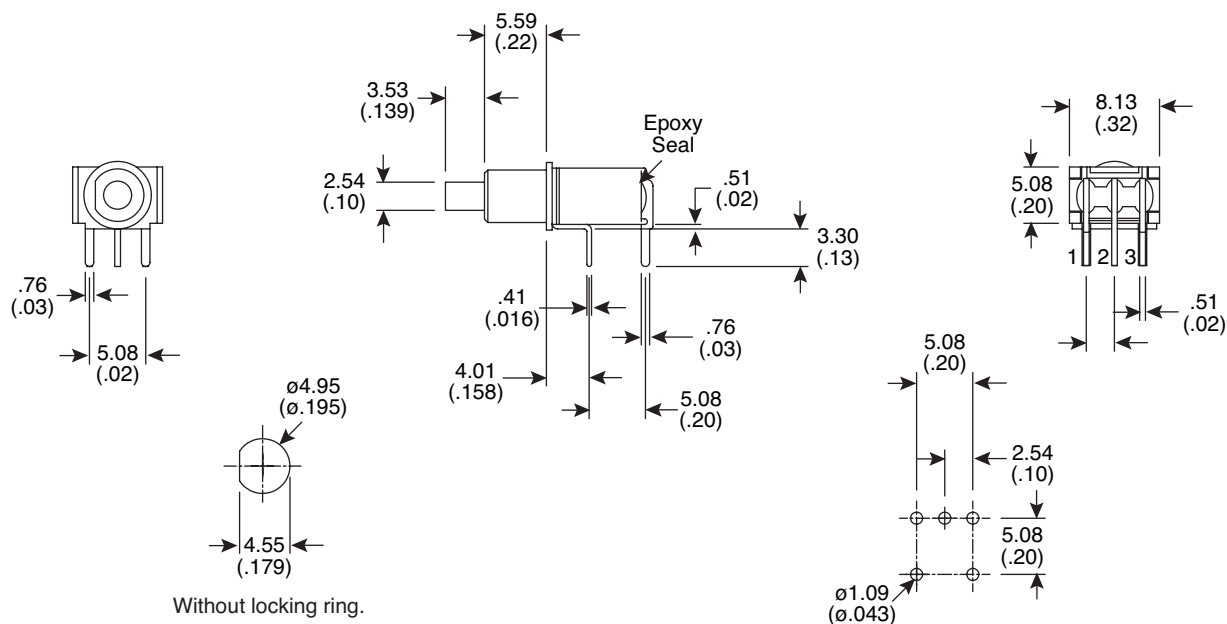

PANEL MOUNTING

P.C. MOUNTING

Electrical Specifications:

- Rating: 1/250VAC, 3/120VAC or 28 VDC
- Contact Resistance: 20mΩmax. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩmin.
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Mechanical Life: 60,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Note:

- RoHS compliant by exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Plunger: Thermoplastic Polyester-black
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Contact: Brass, silver or gold plated
- Terminal: Brass, Silver plated
- Terminal Support: Brass, tin plated

Sub-Miniature Pushbutton Switch
107-3023-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[107-3023-EVX](#)