
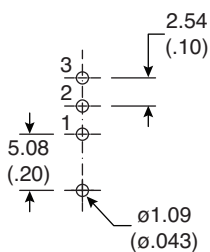





Dimensions: mm (in.)

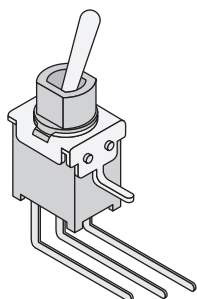

P.C. Mounting

POS.1	POS.2
ON	(ON)
2-3	2-1

Switch Function

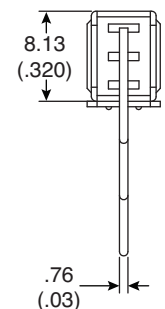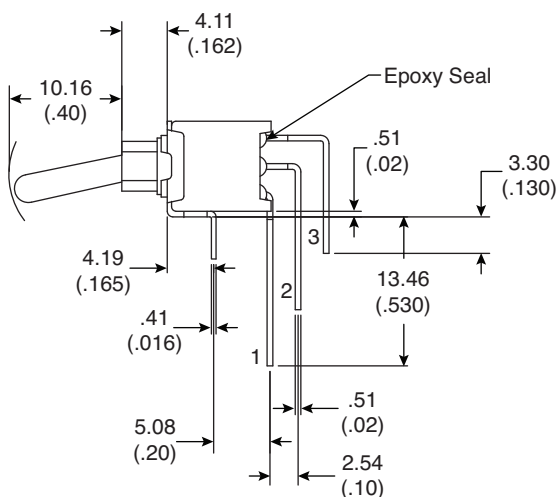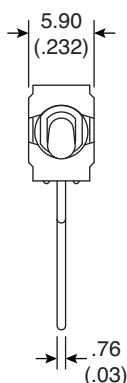

Electrical Specifications:

- Contact resistance: 20m Ω max. initial @ 2-4VDC 100mA
- Insulation resistance: 1,000M Ω min.
- Dielectric strength: 1,000 V RMS@sea level
- Rating: 1A / 250VAC; 3A / 120VAC or 28VDC

Mechanical Specifications:

- Mechanical life: 50,000 make-and-break cycles
- Operating temperature: -30°C to 85°C

Note:

- RoHS Compliant by Exemption

Soldering Process:

- Manual soldering: use soldering iron of 30W, controlled at 350°C approx. 5 seconds while applying solder
- Wave soldering: recommended soldering temp.: 260 $\pm$ 5°C Duration of solder immersion: 5 $\pm$ 1 seconds (PCB is 1.6mm in thickness)

Sealed Sub-Miniature Toggle Switch
108-2AS2T1716-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-2AS2T1716-EVX](#)