
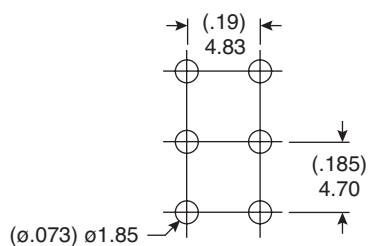


Dimensions: mm (In)

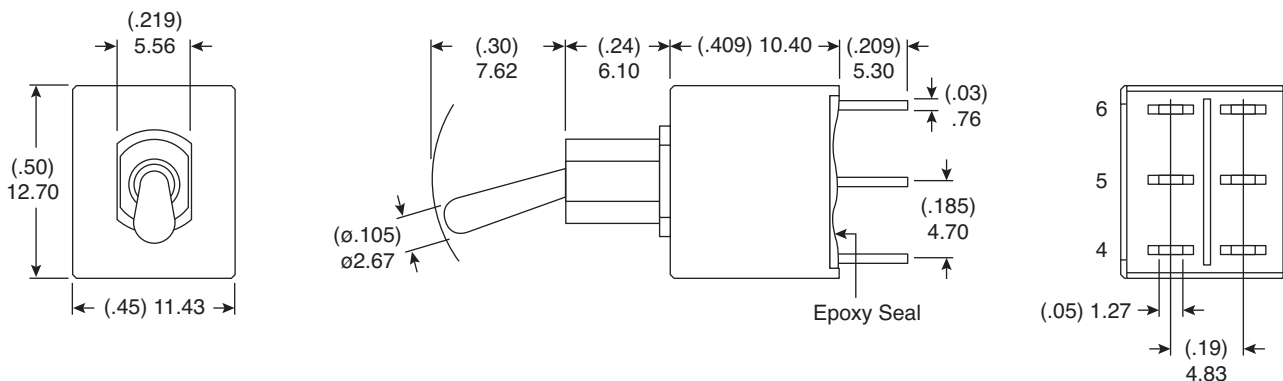

P. C. MOUNTING

Pos. 1	Pos. 2	Pos. 3
ON	OFF	ON
2-3, 5-6		2-1, 5-4
	OPEN	

SWITCH FUNCTION

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Electrical Specifications:

- Contact Resistance: 10m Ω max. initial @ 2-4 VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Dielectric Strength: 1,000 V RMS @ sea level
- Rating: 2A/250VAC
5A/120VAC or 28VDC

Note: RoHS compliant by exemption

Sealed Miniature Toggle Switch
108-1AD3T2225-EVX

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1AD3T2225-EVX](#)