

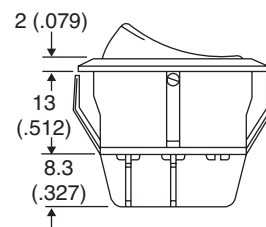
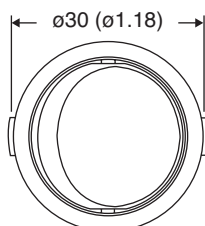
 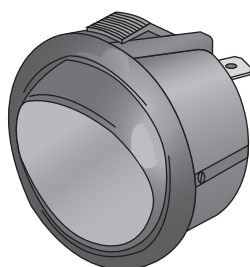
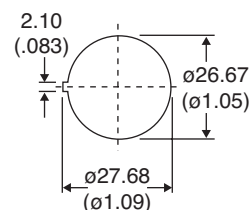



Dimensions: mm (In.)

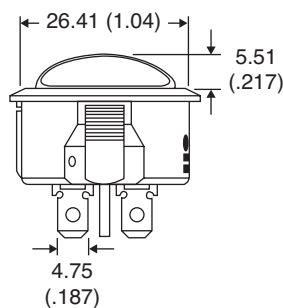

TERMINAL

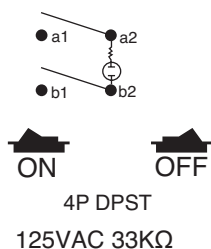

Electrical Specifications:

- Rating: 8A / 125VAC / 250VAC
- Contact resistance: 50mΩ max.
- Insulation resistance: 500VDC 100MΩ min.
- Dielectric strength: 1500VAC for 1 min.

Note:

- RoHS Compliant

Mouser Stock No.	Button
103-R13-245B-02R-EV	Red Illuminated/Neon
103-R13-245B-02G-EV	Green Illuminated/Neon

Illuminated Rocker Switches
103-R13-245B-02R-EV, 103-R13-245B-02G-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-R13-245B-02R-EV](#) [103-R13-245B-02G-EV](#)