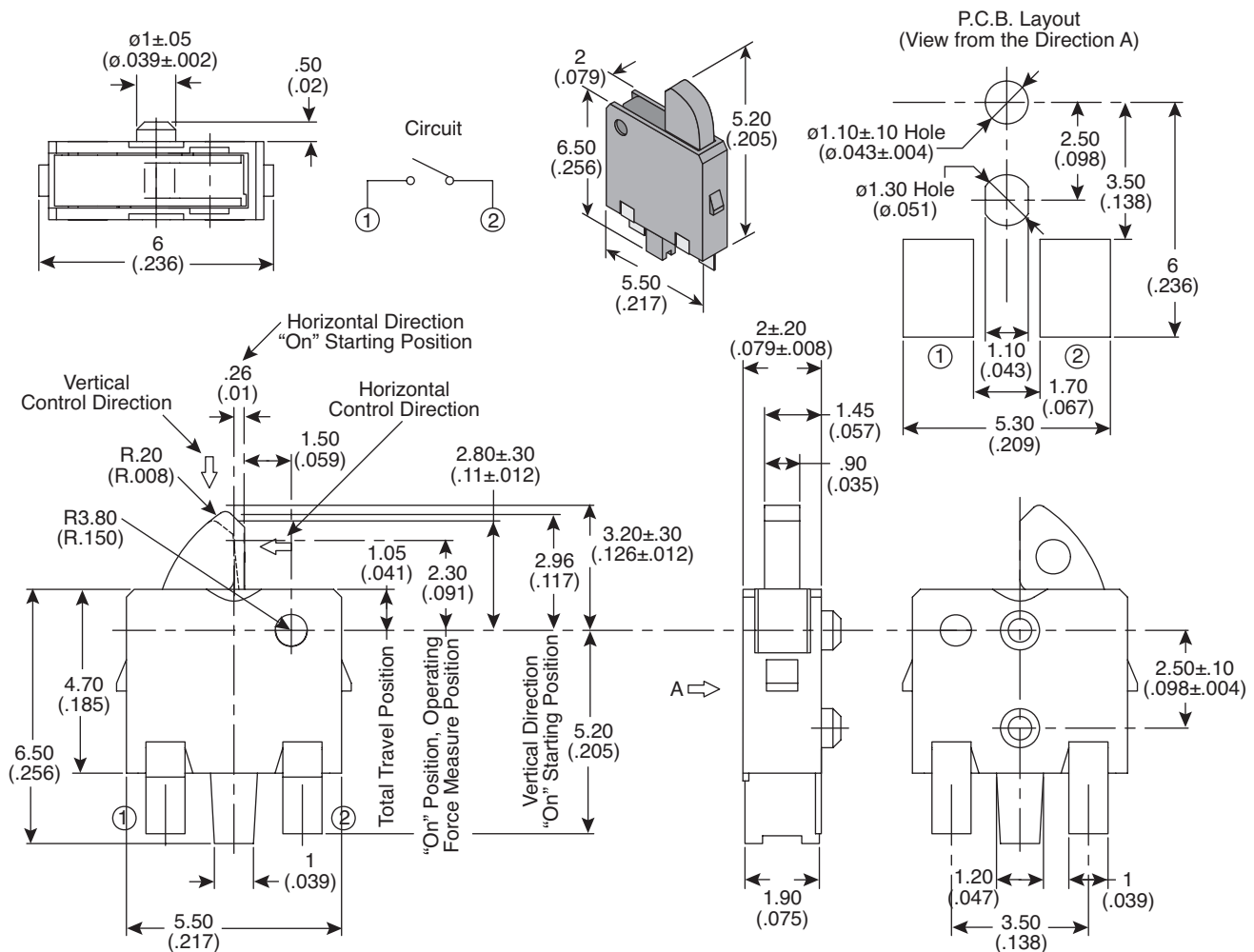


Dimensions: mm (in.)

**Electrical Specifications:**

- Rating: 50mA/20V DC
- Contact Resistance: 1Ω Max.
- Insulation Resistance: 100M Ω Min.
- Dielectric Strength: 100 VAC (50Hz or 60Hz) shall be applied across terminals and cover for 1 minute
- Electrical Life: 50,000 cycles

Mechanical Specifications:

- Operating Temperature: -10°C to $+60^{\circ}\text{C}$.
- Operation Force: 40gf Max.
- Storage Temperature: -20°C to $+70^{\circ}\text{C}$
- Stroke: 2.15mm Max.

Note:

- RoHS Compliant

Detector Switch
104-TEML18-EV

Mountain
Switch

Available from Mouser Electronics

www.mouser.com

1-800-346-6873

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[104-TEML18-EV](#)