


Dimensions: mm (in.)

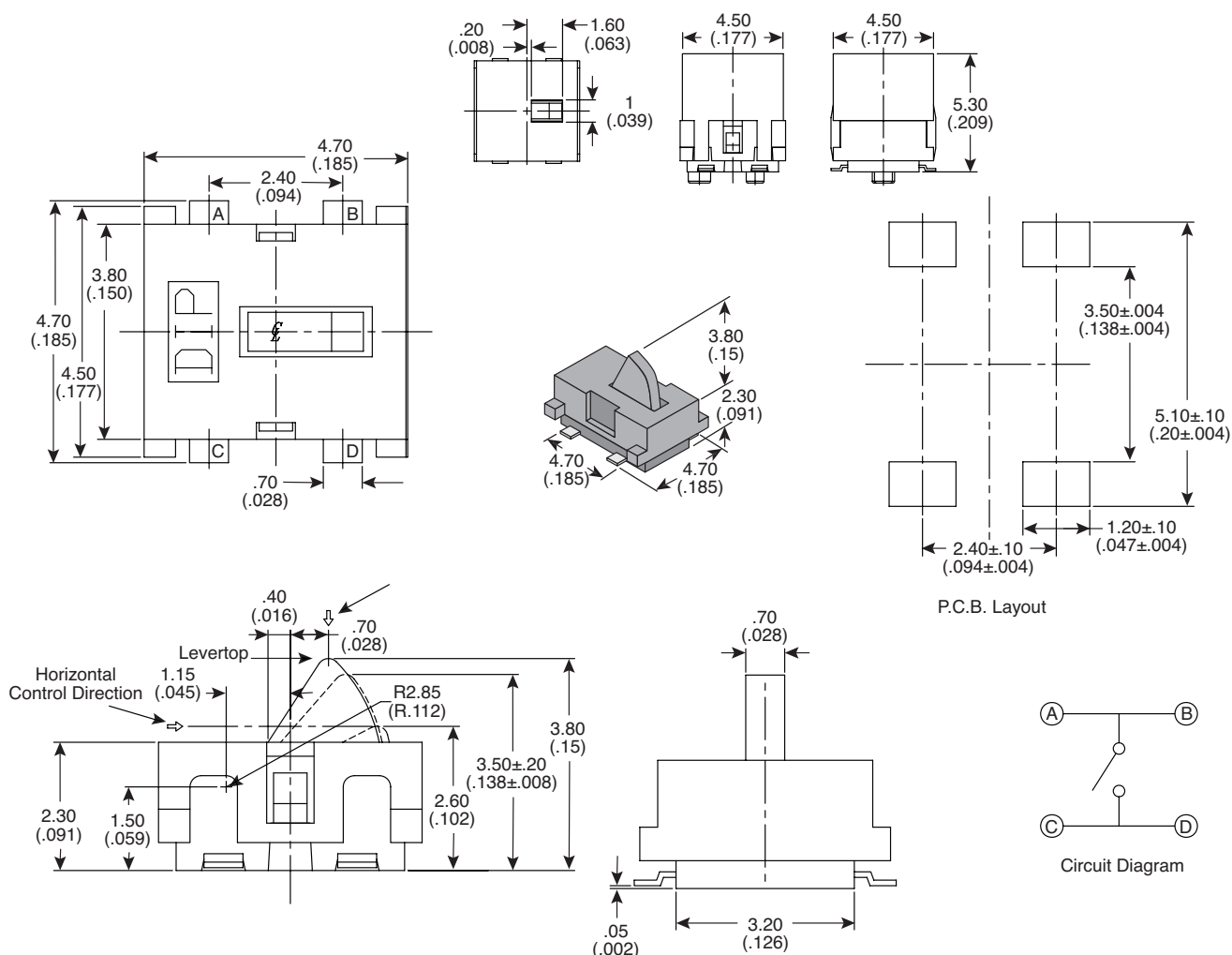

Electrical Specifications:

- Rating: 1mA/5V DC
- Contact Resistance: 1Ω Max.
- Insulation Resistance: 100MΩ Min.
- Dielectric Strength: 100 VAC (50Hz or 60Hz) shall be applied across terminals and cover for 1 minute
- Electrical Life: 100,000 cycles

Mechanical Specifications:

- Operating Temperature: -10° C to +60° C
- Operation Force: 40gf Max.
- Storage Temperature: -20° C to +70° C
- Stroke: 2.60mm Max.

Note:

- RoHS Compliant

Detector Switch
104-ATE2K-EV

**Mountain
Switch**

Available from Mouser Electronics

www.mouser.com

1-800-346-6873

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[104-ATE2K-EV](#)