
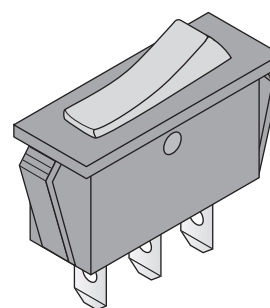
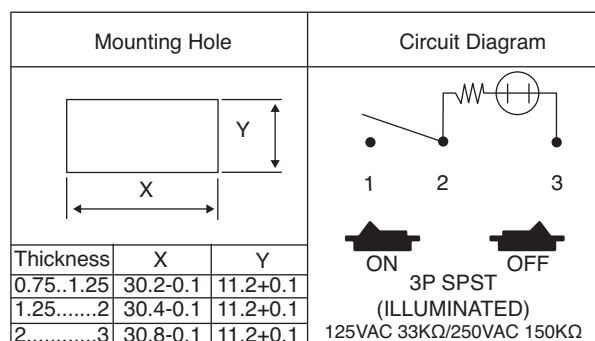


Dimensions: mm (in.)

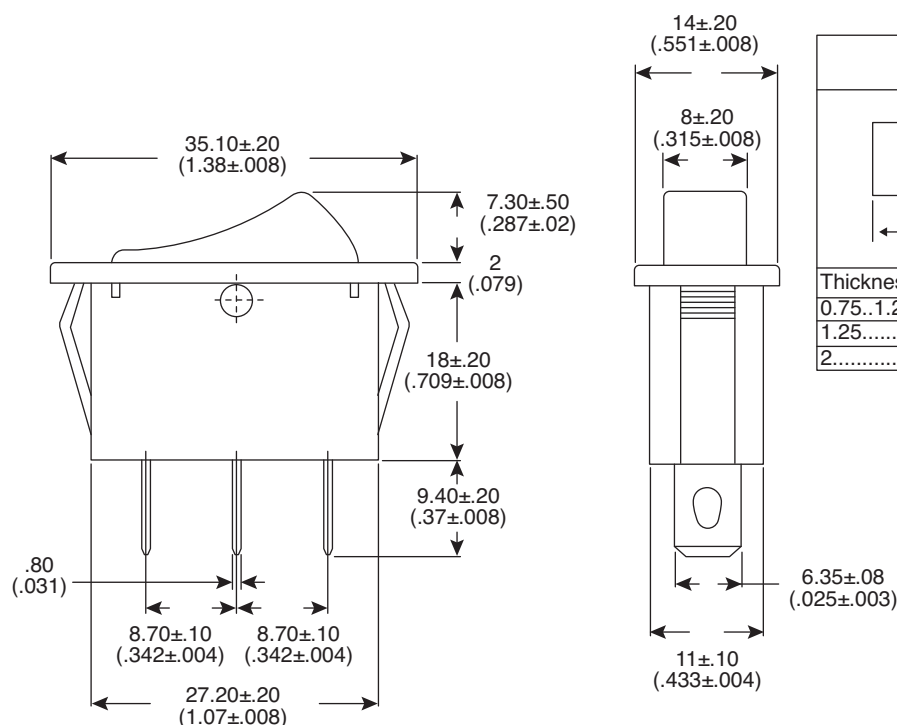

Mouser Stock No.	Button Color
103-7084-EV	Green

Electrical Specifications:

- Rating: 30A / 12VDC
16A / 125VAC, 10A / 250 VAC
- Contact Resistance: 50m Ω max.
- Insulation Resistance: 500 VDC 100M Ω min.
- Dielectric Strength: 1500 VAC 1 minute

Mechanical Specifications:

- Neon Lamps: 110VAC

Materials:

- Frame: Nylon #66, Black
- Neon: ø4, NE-2G
- Resistor: 1/4S, 33kΩ

Note:

- RoHS Compliant

Illuminated Rocker Switch
103-7084-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-7084-EV](#)