



Dimensions: mm (in.)

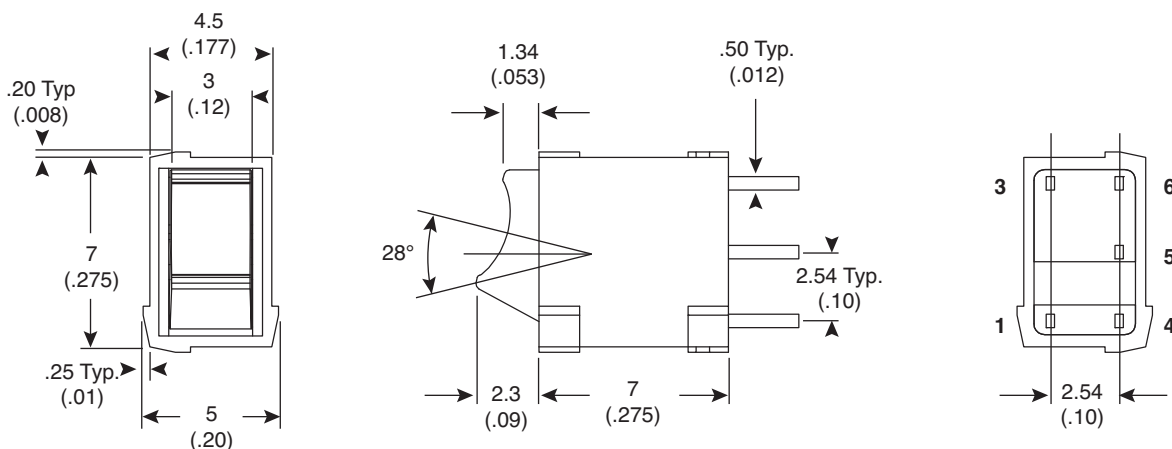

On single pole models positions 1 & 3 are support pins

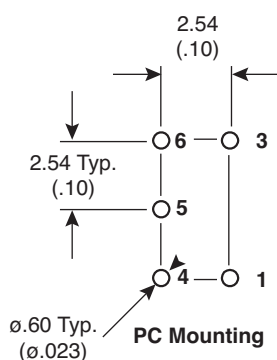

Switch Function

POS.1	POS.2
ON	ON
5-6	5-4
5 Com.	5 Com.

Electrical Specifications:

- Contact Rating: 0.4VA Max. @ 20V AC or DC Max.
- Contact Resistance: Below 100mΩ typ. initial
- Insulation Resistance: 500MΩ min.
- Dielectric Strength: 500Vrms min.

Mechanical Specifications:

- Life: 40,000 make-and-break cycles
- Operating Temperature: -30°C~+85°C

Soldering Process:

- Only for Wave Soldering, do not use in IR-Reflow Soldering

Note:

- RoHS Compliant

Sealed Sub-Miniature Rocker Switch

103-7136-EV

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-7136-EV](#)