


Dimensions: mm (in.)

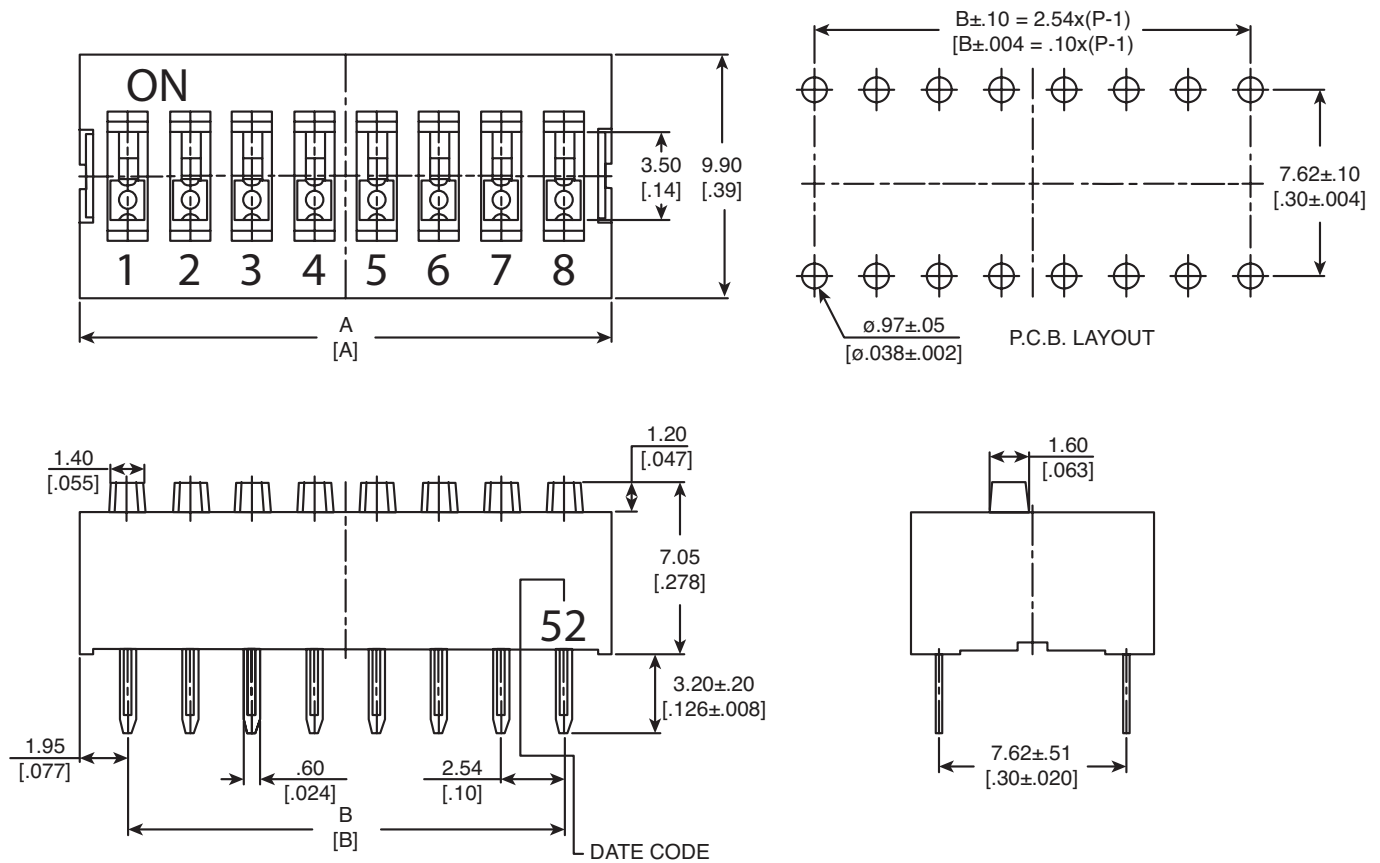

Mountain Switch Part No.	No. of Positions	Dim. A	Dim. B
106-SDN02-EV	2	6.44 [.254]	2.54 [.10]
106-SDN04-EV	4	11.52 [.454]	7.62 [.30]
106-SDN06-EV	6	16.60 [.654]	12.70 [.50]
106-SDN08-EV	8	21.68 [.854]	17.78 [.70]

Mechanical Specifications:

- Operating Temperature Range: -40°C ~ +85°C
- Storage Temperature Range: -40°C ~ +85°C

Electrical Specifications:

- Rating: Switching: 25mA/24VDC
Non-Switching: 100mA/50VDC
- Contact Resistance: 50mΩ Max. (initial)
- Insulation Resistance: 100MΩ Min.
- Dielectric Strength: 500VAC (50Hz or 60Hz)
for 1 minute

Soldering Process:

- Manual Soldering:
Soldering Temperature: Max. 350°C
Continuous Soldering Time: Max. 5 seconds

Note:

- RoHS Compliant

DIP Switches

106-NDV02-EV, 106-NDV04-EV,
106-NDV06-EV, 106-NDV08-EV

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[106-NDV06-EV](#) [106-NDV08-EV](#) [106-NDV04-EV](#) [106-NDV02-EV](#)