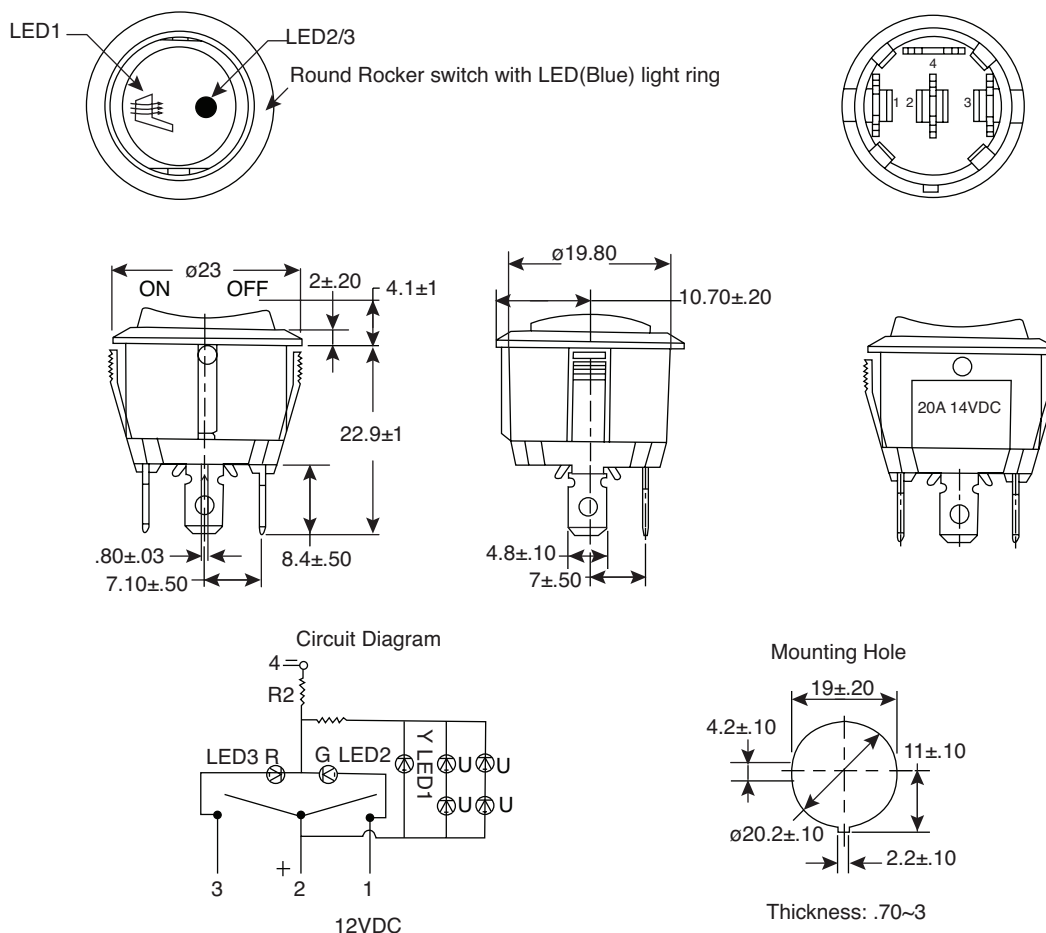


DIMENSIONS: mm

**Electrical Specifications:**

- Rating: 20A/14VDC
- Contact Resistance: 50mΩ Max.
- Insulation Resistance: 500VDC 100MΩ Min.
- Dielectric Strength: 1500V AC for 1 min.

Materials:

- Frame: Blue Clear, PC
- Actuator: White Diffused, PC with Black Painting
- LED1: Yellow Light (always on)
- LED2/3: Green/Red (when load is on)

Mechanical Specifications:

- Operating Temperature Range: -25°~85° C
- Circuit: 4P SPDT ON-OFF-ON (LED dependant)

Note:

- RoHS Compliant

Illuminated Rocker Switch

103-R13-273D-BGR-EV

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-R13-273D-BGR-EV](#)