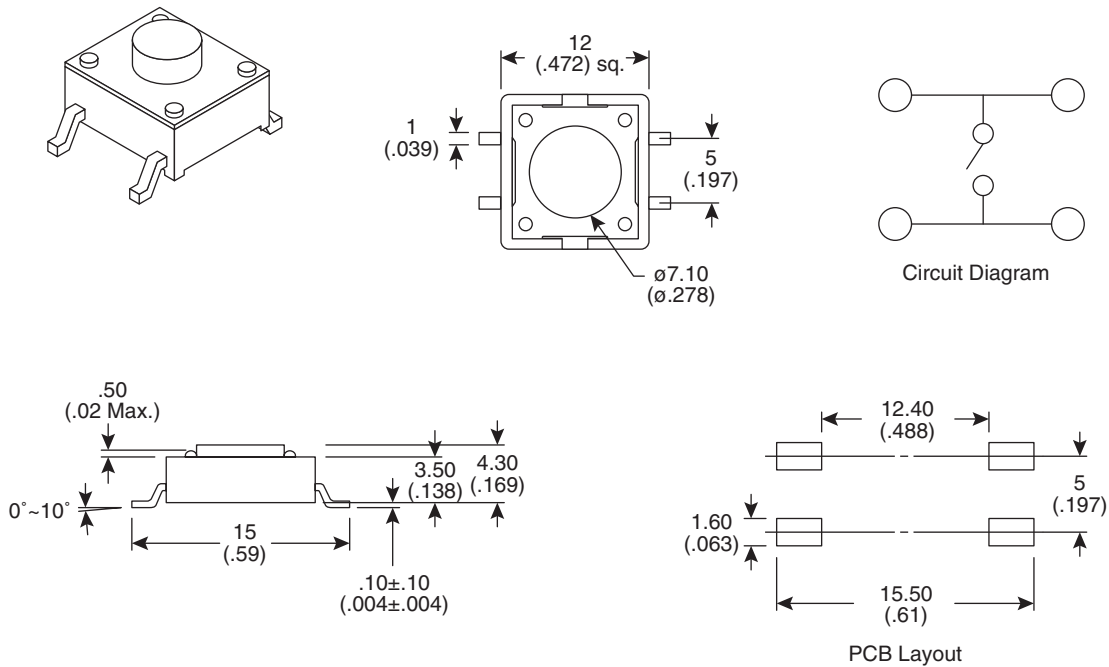


**DIMENSIONS: mm (in.)****Electrical Specifications:**

- Rating: 50mA/12VDC
- Life: 500,000 cycles
- Contact resistance: 100m $\Omega$  max.
- Insulation resistance: 100M $\Omega$  min. @ 500VDC
- Dielectric Strength: 250VAC for 1 minute

**Mechanical Specifications:**

- Type: SPST surface mount, tactile
- Operating force: 160 $\pm$ 50g
- Operating temperature: -25 $^\circ$ ~+70 $^\circ$ C
- Storage temperature: -30 $^\circ$ ~+80 $^\circ$ C
- Travel: .012 $\pm$ .004"(.30 $\pm$ .10mm)

**Materials:**

- Cover: tin plated steel
- Contacts: silver clad phosphor bronze
- Terminals: silver clad brass
- Base: nylon, brown
- Stem: nylon, brown

**Note:**

- RoHS Compliant and are also process compatible with 260 $^\circ$  solder

**Tactile Switch (SMT)**  
101-0124-EV

**Mountain**  
**Switch**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eagle Plastic Devices:](#)

[101-0124-EV](#)