


Dimensions: mm (In.)

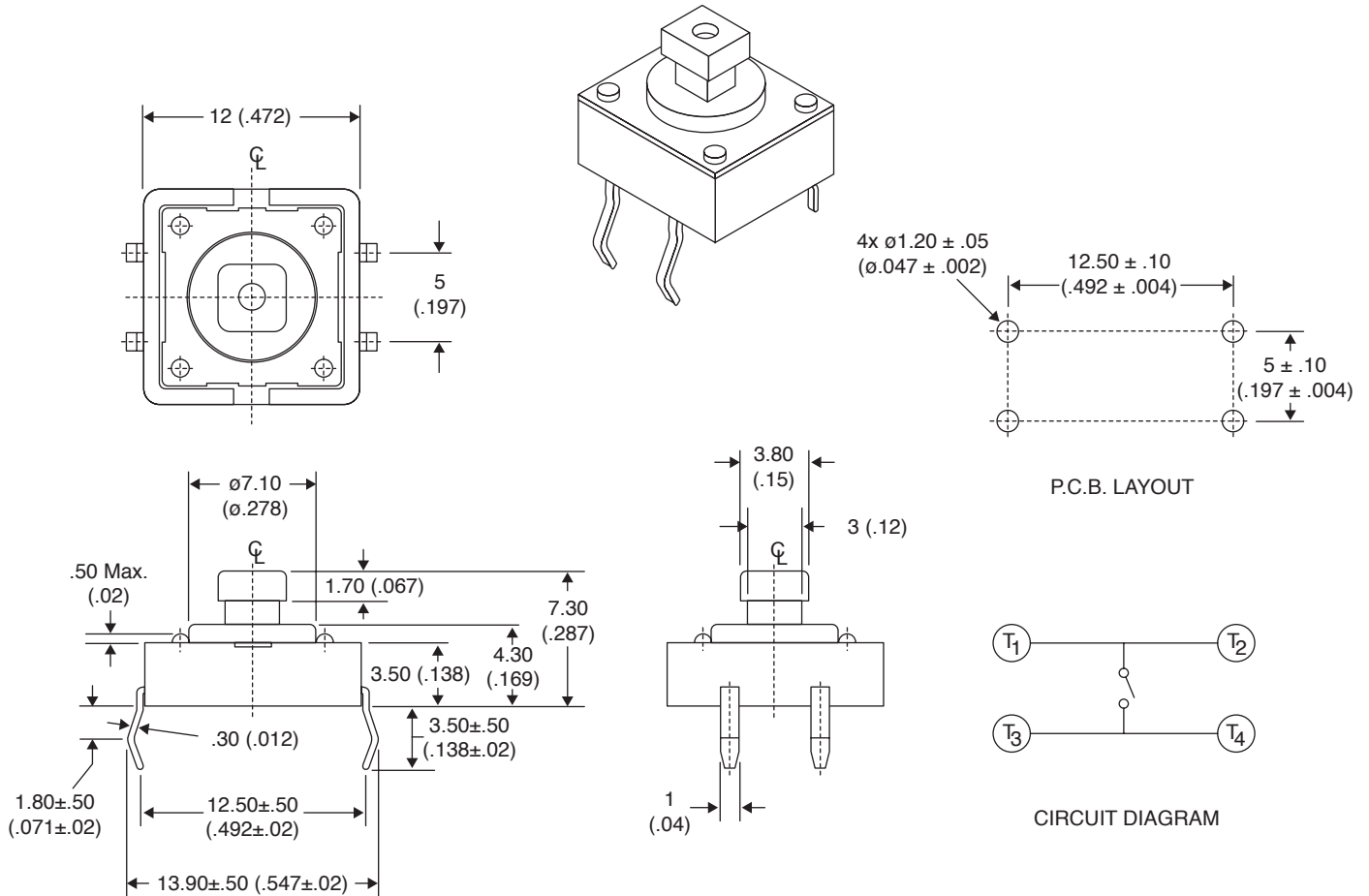

**Electrical Specifications:**

- Rating: 50mA / 12VDC
- Contact Resistance: 100mΩ Max.
- Insulation Resistance: 100MΩ Min.
- Dielectric Strength: 250VAC for 1 Minute

**Mechanical Specifications:**

- Operating Life: 50,000 Cycles
- Operating Temperature: -25°C to +70°C

**Note:**

- RoHS Compliant and Process Compatible with 260° solder

**Tactile Switches**

101-TS6211T2602AC-EV, 101-TS6211T3202AC-EV



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eagle Plastic Devices:](#)

[101-TS6211T2602AC-EV](#)

[Mountain Switch:](#)

[101-TS6211T3202AC-EV](#)