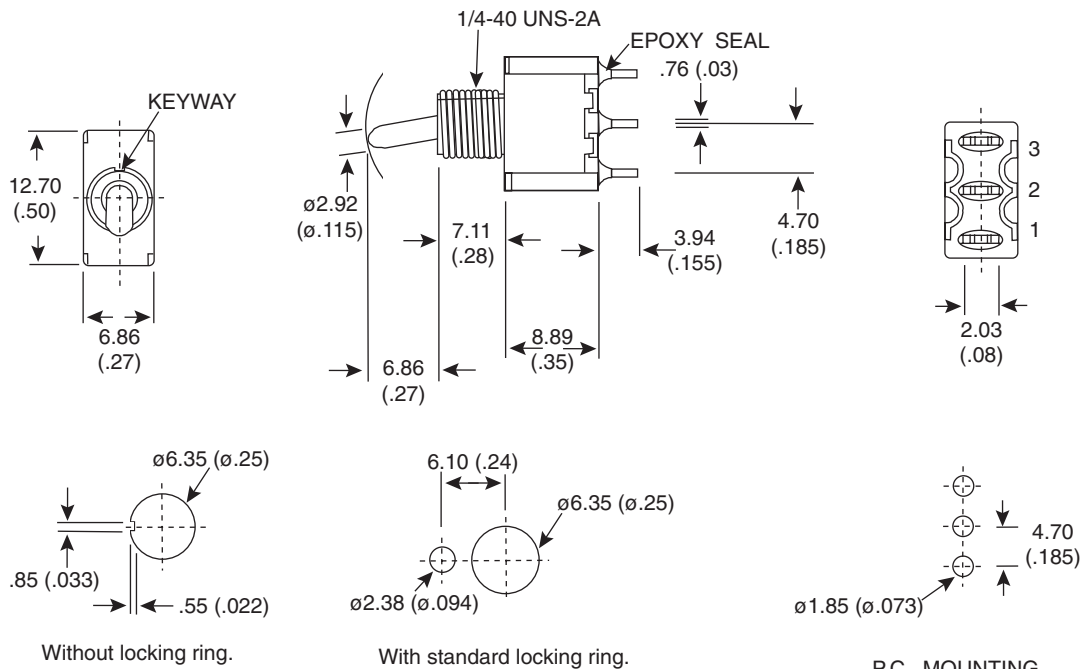


DIMENSIONS: mm (in.)

PANEL MOUNTING

P.C. MOUNTING

POS.1	POS.2
ON	ON
2-3	2-1

SWITCH FUNCTION

Electrical Specifications:

- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Rating: 2A / 250 VAC; 5A / 120 VAC or 28 VDC
- Dielectric Strength: 1,000 V RMS@ sea level

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Note:

- RoHS Compliant by Exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver plated

Toggle Switch
108-1MS1T2B3M2QE-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-1MS1T2B3M2QE-EVX](#)