


Dimensions: mm (in.)

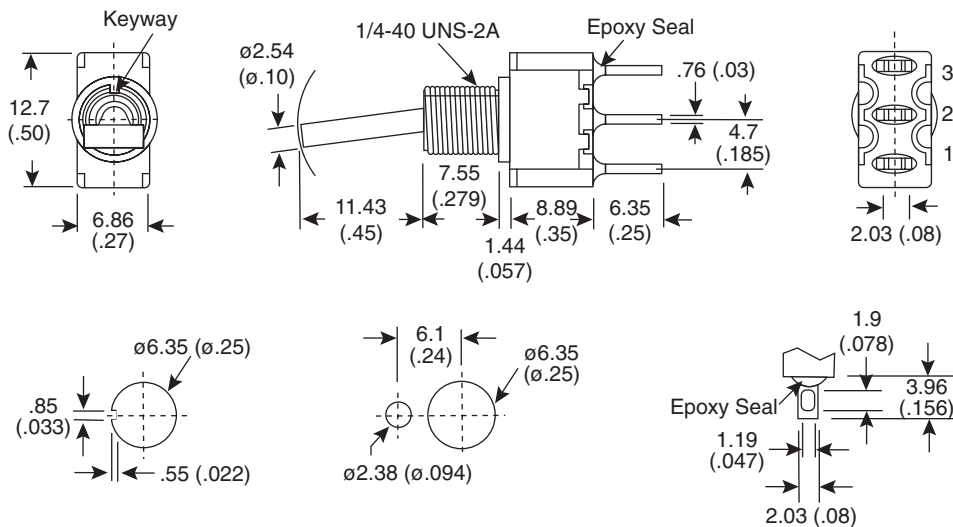

Without locking ring.

With standard locking ring.

PANEL MOUNTING

SOLDER LUG

POS.1	POS.2
ON	(ON)
2-3	2-1

SWITCH FUNCTION

**Mechanical Specifications:**

- Operating Temperature: -30°C to +85°C

**Note:**

- RoHS Compliant by Exemption

**Electrical Specifications:**

- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Rating: 2A/ 250VAC, 5A/ 120VAC or 28VDC
- Dielectric Strength: 1,000 V RMS@ sea level

**Materials:**

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver plated.

**Toggle Switch**  
108-1MS2T6B1M1QE-EVX



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1MS2T6B1M1QE-EVX](#)