


Dimensions: mm (in.)

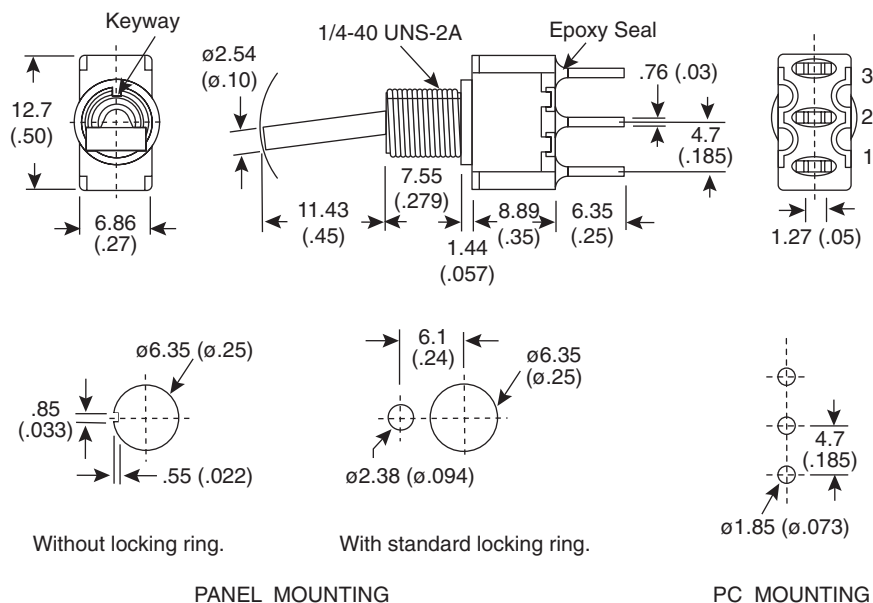

| POS.1 | POS.2 |
|-------|-------|
| | |
| ON | (ON) |
| 2-3 | 2-1 |
| | |

SWITCH FUNCTION

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Note:

- RoHS Compliant by exemption

Electrical Specifications:

- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Rating: 2A/ 250VAC, 5A/ 120VAC or 28VDC
- Dielectric Strength: 1,000 V RMS@ sea level

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver plated.

Toggle Switch
108-1MS2T6B1M2QE-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-1MS2T6B1M2QE-EVX](#)