

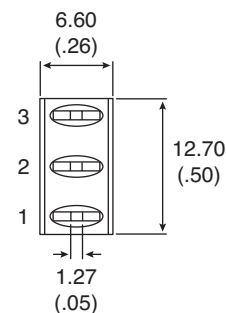
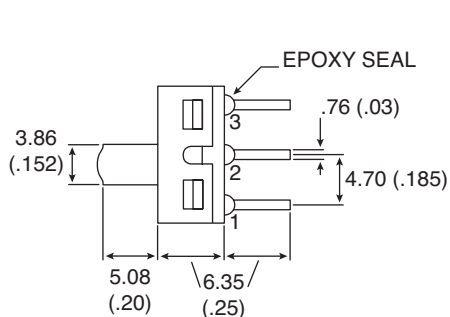


Dimensions: mm (In.)

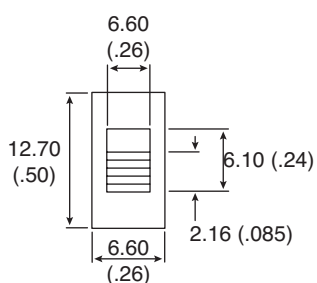

P.C. MOUNTING

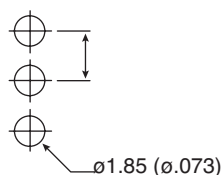

POS. 1	POS. 2	POS. 3
ON	NONE	ON
2-1	OPEN	2-3

SWITCH FUNCTION

Electrical Specifications:

- Rating: 2A/250VAC; 5A/120VAC or 28VDC
- Contact Resistance: 10mΩ Max. initial @2-4VDC 100mA
- Insulation Resistance: 1,000MΩ Min.
- Dielectric Strength: 1,000 V RMS@ Sea Level

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Materials:

- Case: Dially Phthalate (DAP)
- Actuator: Nylon, Black std.
- Housing: Stainless Steel
- Contact: Silver or Gold Plated
- Terminal Seal: Epoxy

Note:

- RoHS compliant

Slide Switch
103-5016-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-5016-EV](#) [103-5016-EVX](#)