
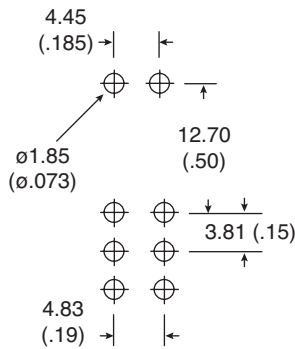


Dimensions: mm (In.)

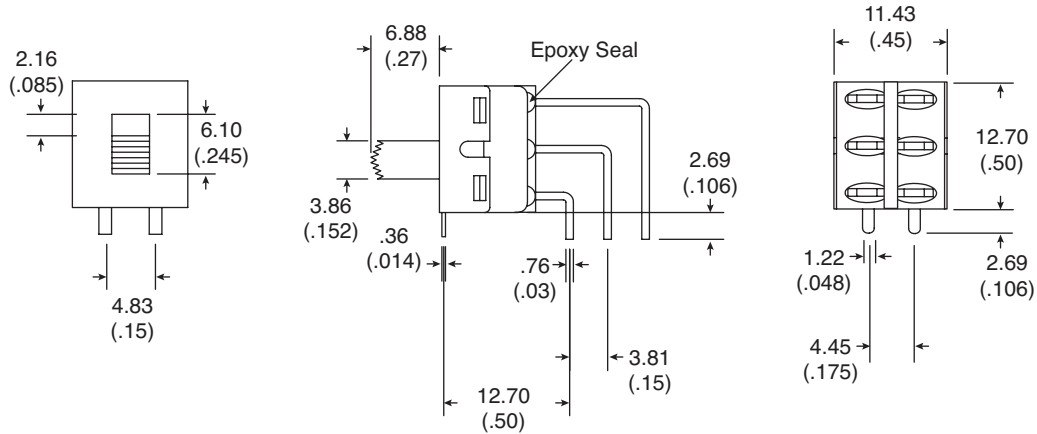

P.C. MOUNT

POS. 1	POS. 2	POS. 3
ON	NONE	ON
2-1, 5-4	OPEN	2-3, 5-6

SWITCH FUNCTION

**Electrical Specifications:**

- Rating: 2A/250VAC, 5A/120VAC or 28VDC
- Contact Resistance: 10m $\Omega$  max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M $\Omega$  min.
- Dielectric Strength: 1,000 V RMS @ sea level

**Materials:**

- Case: Dially phthalate (DAP)
- Actuator: Nylon, Black Std.
- Housing: Stainless Steel
- Contact: Silver or Gold Plated
- Terminal Seal: Epoxy

**Mechanical Specifications:**

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

**Note:**

- RoHS Compliant

Slide Switch  
103-5013-EV



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-5013-EVX](#) [103-5013-EV](#)