
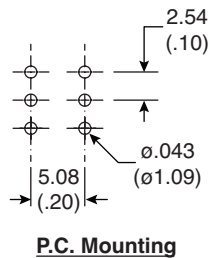


## Dimensions: mm (In.)

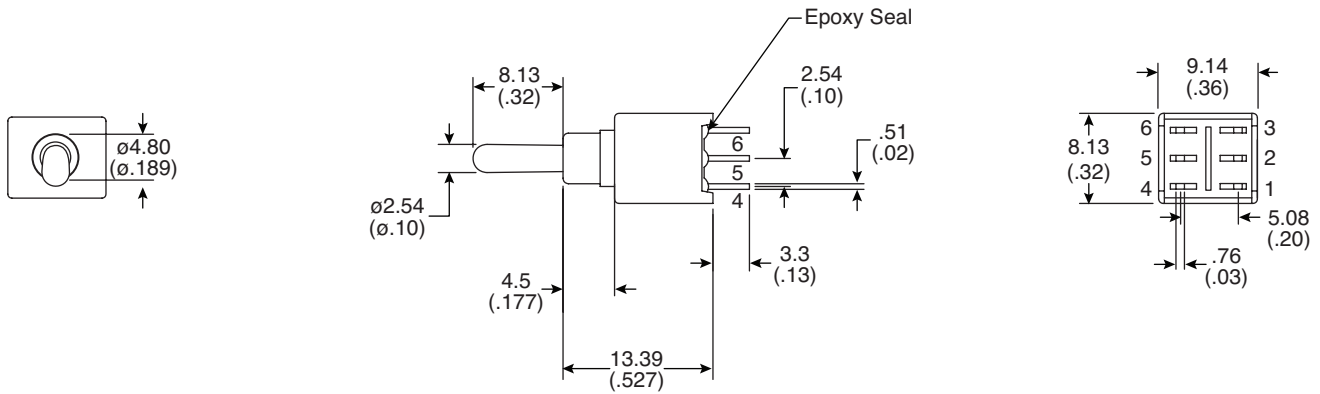

POS.1	POS.2	POS.3
ON	OFF	ON
2-3, 5-6	OPEN	2-1, 5-4

Switch Function

**Electrical Specifications:**

- Contact resistance: 20mΩ max. initial @ 2-4VDC 100mA
- Insulation resistance: 1,000MΩ min.
- Dielectric strength: 1,000 V RMS@sea level
- Rating: 1A / 250VAC; 3A / 120VAC or 28VDC

**Mechanical Specifications:**

- Mechanical life: 50,000 make-and-break cycles
- Operating temperature: -30°C to 85°C

**Note:**

- RoHS Compliant by Exemption

**Sealed Sub-Miniature Toggle Switch**  
108-2AD3T3238-EVX

**Mountain**  
**Switch**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

108-2AD3T3238-EVX