


Dimensions: mm (in.)

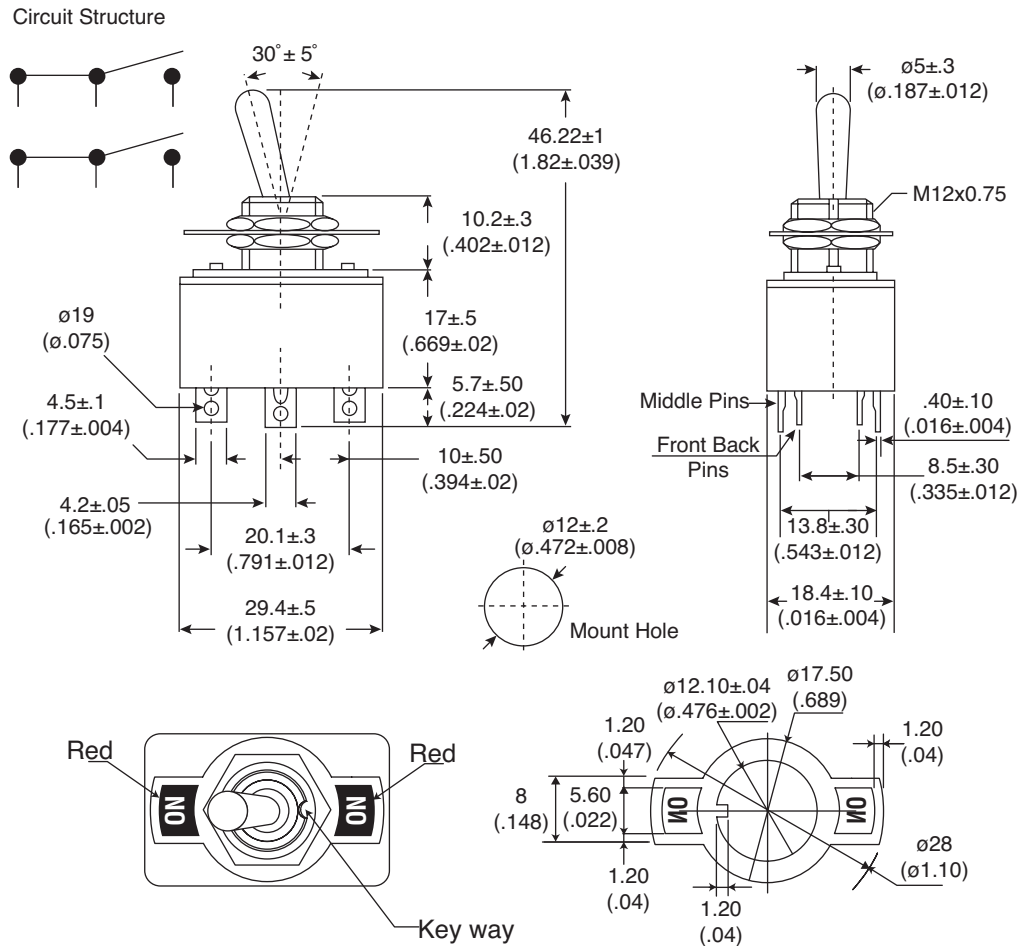

Electrical Specifications:

- Rating: 3A/125VAC; 1.5A/250VAC
- Contact Resistance: 50m Ω max.
- Insulation Resistance: 500V DC 100M Ω min.
- Dielectric Strength: 1000V AC 1 minute

Mechanical Specifications:

- Circuit: 6P DPDT On-On

Note:

- RoHS Compliant by Exemption

Toggle Switch
103-0008-EVX

Mountain Switch

Available from Mouser Electronics

www.mouser.com

1-800-346-6873

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-0008-EVX](#)