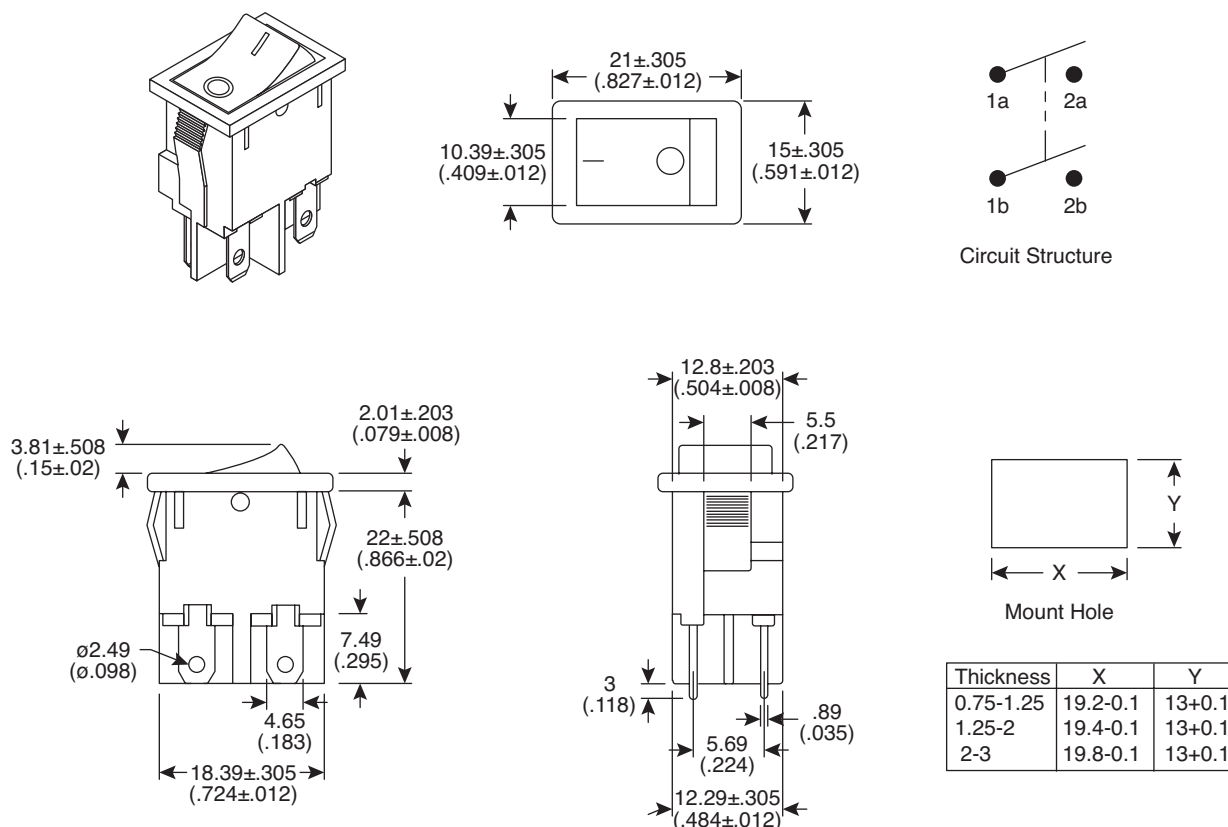


Dimensions: mm (In)

**Mechanical Specifications:**

- Circuit: 4P, DPST, On-Off
- Temperature Range: -20°C ~ +70°C
- Environmental Standard: 5°C~35°C and 40%~85% R.H. If there are problems related to judgement, the reference condition shall be 25 $\pm$ 2°C and 65 $\pm$ 5% R.H.
- Operating Force (application of load to the tip of button in operating direction): 600 $\pm$ 150gf

Note:

- RoHS Compliant

Electrical Specifications:

- Rating: 6A/250VAC, 10A/125VAC
- Contact Resistance: 30m Ω max. / 5VDC 1A
- Insulation Resistance: 100M Ω min. / 500VDC
- Dielectric Strength: 1500VAC for 1 minute
- Surge Current (in use of capacitive load): 111A/250VAC, 1/240 sec.

Rocker Switch
103-R13-73A-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-R13-73A-EV](#)