
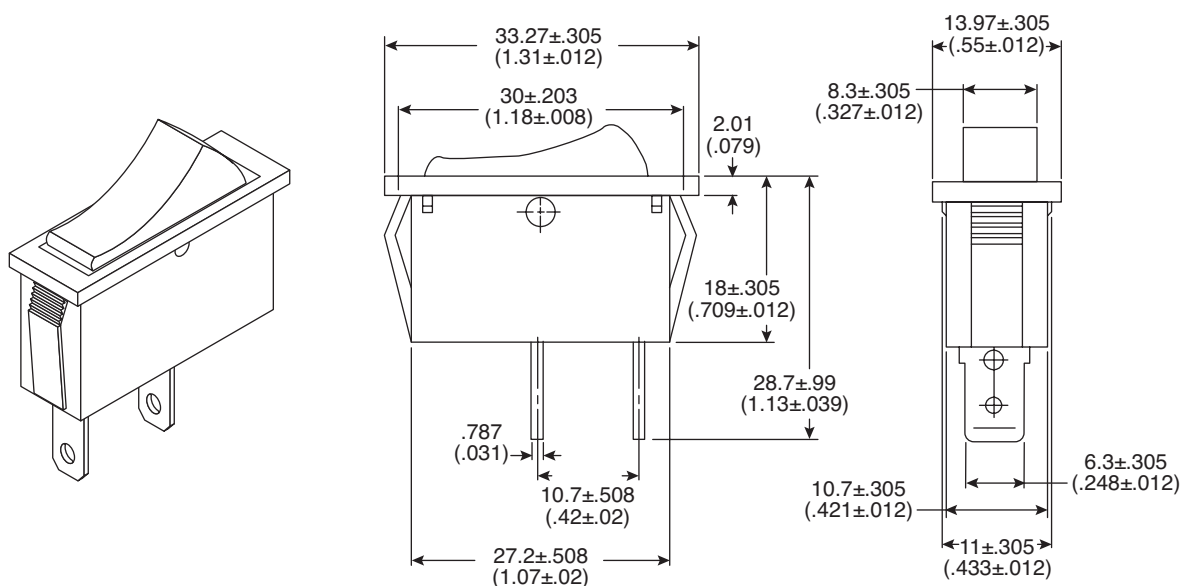


Dimensions: mm (In)

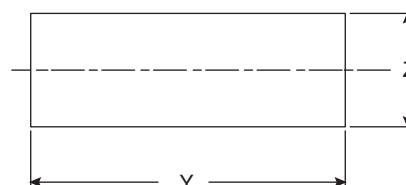

Panel Access Hole Cut Out Data

Panel Thickness	Y	Z
.030 to .049	1.189 $\pm$.004	.441 $\pm$.004
.049 to .079	1.197 $\pm$.004	.441 $\pm$.004
.079 to .118	1.213 $\pm$.004	.441 $\pm$.004

**Electrical Specifications:**

- Rating: 16A/125VAC 1/8 HP, 10A/250VAC 1/3 HP; 20A/12VDC
- Contact Resistance: 50m Ω max.
- Insulation Resistance: 500VDC 100M Ω min.
- Dielectric Strength: 1500VAC for 1 minute

Mechanical Specifications:

- Circuit: 2P SPST On-Off

Note:

- RoHS Compliant

Rocker Switch
103-R13-91A-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[103-R13-91A-EV](#)