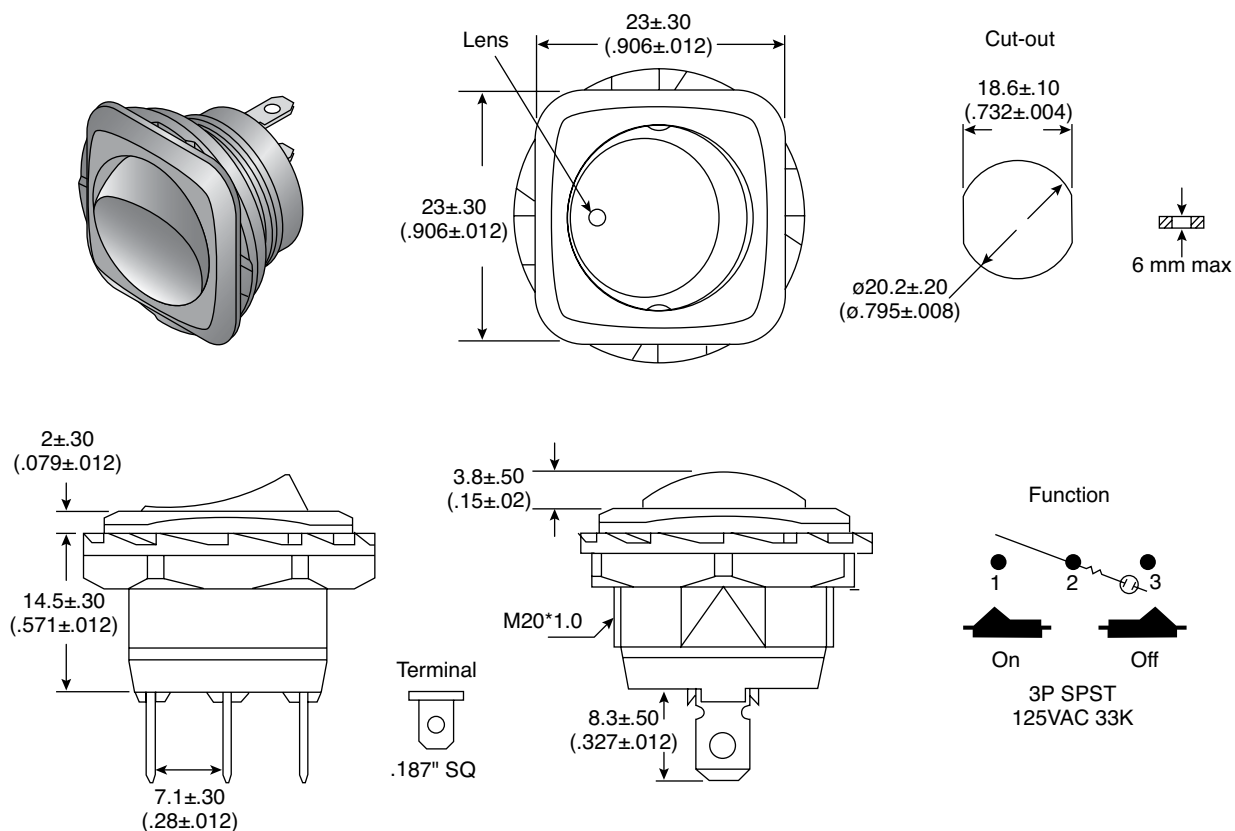


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 16A/125VAC, 10A/125VAC
- Contact Resistance: 50mΩ Max
- Insulation Resistance: 500VDC 100MΩ min.
- Dielectric Strength: 1500VAC for 1 minute

Note:

- RoHS Compliant
- Button: Illuminated Red Spot Neon

Illuminated Rocker Switch
103-R13-135B2-02R-EV

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-R13-135B2-02G-EV](#) [103-R13-135B2-02R-EV](#)