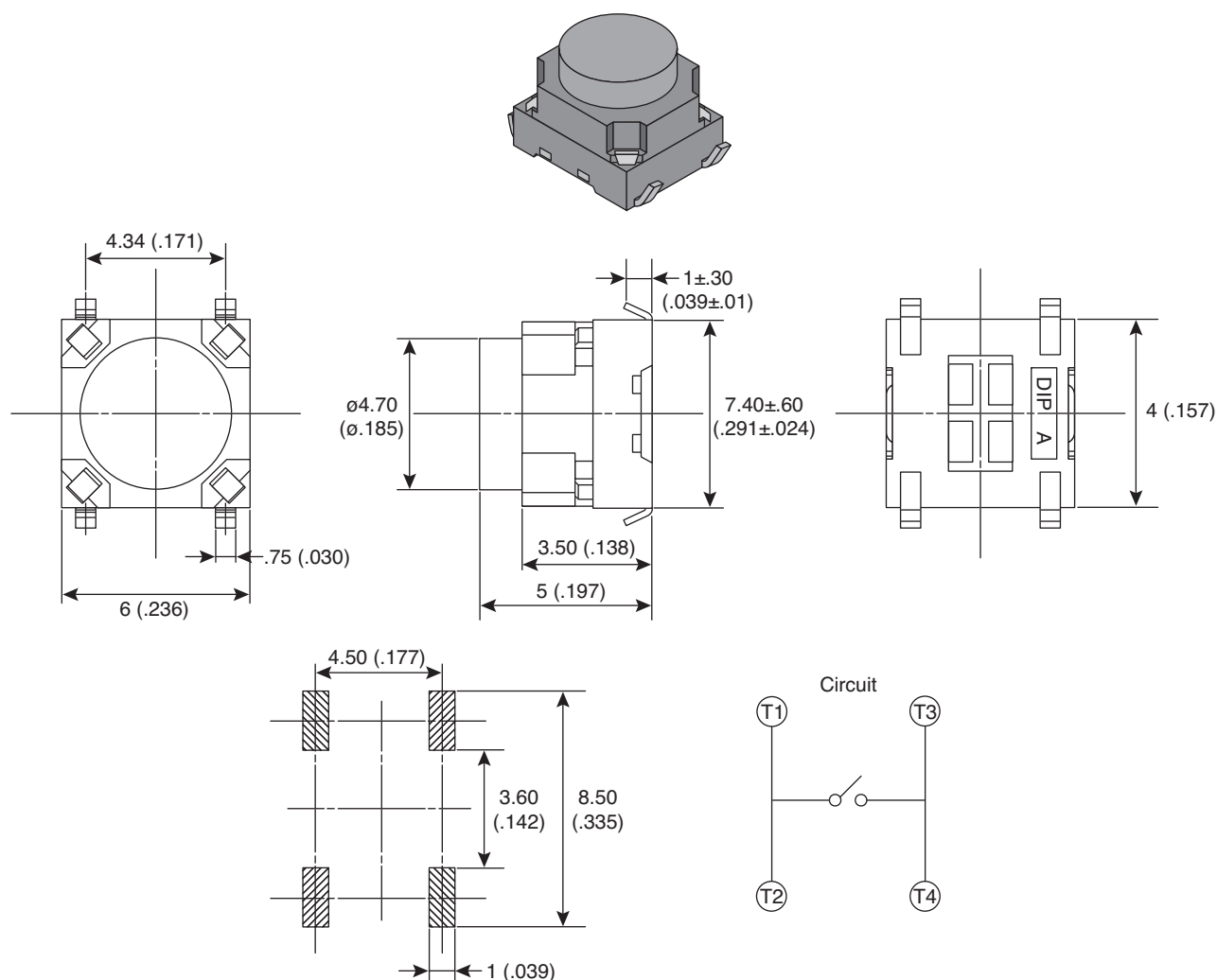


Dimensions: mm (in.)

**Electrical Specifications:**

- Rating: 50mA/12VDC
- Dielectric Strength: 300 V AC(50Hz or 60Hz) for 1 minute
- Contact Resistance: 100mΩ max.
- Insulation Resistance: 500VDC 100MΩ min.

Note:

- RoHS Compliant

Mechanical Specifications:

- Operating Temperature: -40° C to +85° C
- Storage Temperature: -40° C to +85° C
- Stroke: 1.30 ± .30mm

Mouser Stock No.	Mechanical Life (cycles)	Operating Force
101-L613R-EV	100,000	200 ± 50gf
101-L613S-EV	30,000	350 ± 100gf

Tactile Switches
101-L613R-EV, 101-L613S-EV

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[101-L613R-EV](#) [101-L613S-EV](#)