


DIMENSIONS: mm (in.)

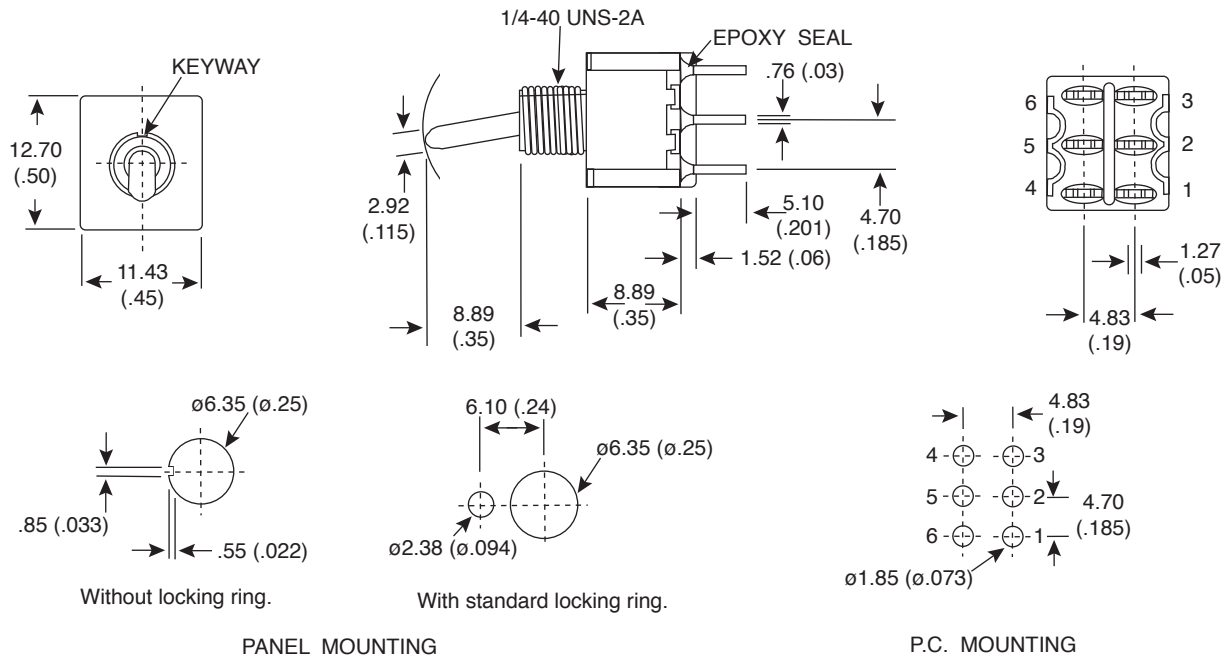

PANEL MOUNTING

P.C. MOUNTING

SWITCH FUNCTION

POS.1	POS.2	POS.3
ON	NONE	(ON)
2-3,5-6	N/A	2-1,5-4

Electrical Specifications:

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10m Ω max. initial @ 2-4VDC
100mA for both silver and gold plated contacts
- Insulation Resistance: 1,000M Ω min.
- Dielectric Strength: 1,000 V RMS@ sea level
- Rating: 2A / 250 VAC
5A / 120 VAC or 28 VDC

Mechanical Specifications:

- Operating Temperature: -30° C to +85° C

Note:

- RoHS compliant by exemption

Toggle Switch
108-1MD2T1B1M2QE-EVX



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[108-1MD2T1B1M2QE-EVX](#)