



R13-523

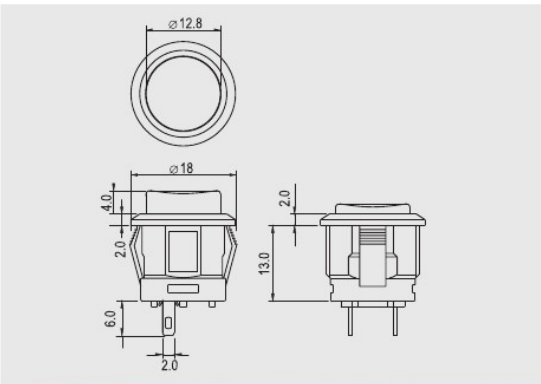

Rating
3A 125V AC 1.5A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out

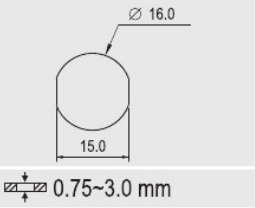

FEATURES

- \* MATERIAL: Frame is nylon (UL flame: 94V-2). Terminals are silver plated brass.
- \* Illuminated actuators are molded in PC, available with red, amber, green, blue and white colors.
- \* Snap-in mounting, easy to install switch into panel.
- \* Same mounting hole as R13-555, but in different shape of bezel and button.

R13-523     -    

FUNCTION		BUTTON	TERMINAL
<b>A</b>  OFF 2P SPST (ON)	<b>B</b>  OFF 2P SPST ON	<input checked="" type="checkbox"/> W/O LED	<span style="border: 1px solid red; padding: 2px;">0 5  SO</span>
		<input type="checkbox"/> With LED (LED INDEPENDENT)	

\* ( ) =momentary

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[R13-523A05-BB](#)