

# A13-228

NEW

USB



## FEATURES

### \* RATING

Input: 12V/24V DC.

USB output: 5V DC 2.1A+2.1A max, 2 ports.

QC 3.0 output: 5V/3A, 9V/2A, 12V/1.5A  $\pm 10\%$

### \* MATERIAL

Housing: ABS.

Top contact: nickel plated metal.

Spring contact: nickel plated spring steel.

\* **A13-228BU3**: Black housing, blue cover, yellow LED.

\* **A23-228WB3**: White housing, black cover, yellow LED.

\* Customized logo, printed on housing is available.

\* LED power indicator.

\* With fuse 5A max.


\* Short circuit protection.

\* Over current protection.

\* Over temperature protection.

\* Suitable for most mobile phones and consumer electronic devices.

\* Fits with  $\varnothing 21\text{mm}$  socket.

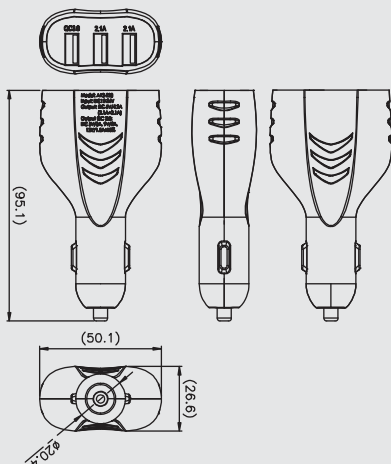

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-228BU3](#)