


R3-9

UL US

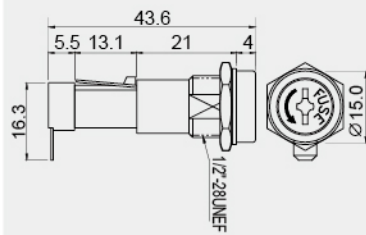

(4.8mm)0.187"
Quick connect

0.5~4.5mm MAX

FEATURES:

- Material:
Frame and cap: PBT(UL flame: 94V-0).
Terminal: tin plated brass.
- Mounted by nut.
- Metal or plastic nut is optional.

A

B


C

C O

CAP	FUSE	RATING
Bayonet type (tool release)	$\varnothing 6.35 \times 30\text{mm}$ $\varnothing 6.35 \times 31.8\text{mm}$	15A 250V AC
Bayonet type (tool release)	$\varnothing 5.0 \times 20\text{mm}$	10A 250V AC
Screw type (tool release)	$\varnothing 6.35 \times 30\text{mm}$ $\varnothing 6.35 \times 31.8\text{mm}$	15A 250V AC
Screw type (tool release)	$\varnothing 6.35 \times 30\text{mm}$ $\varnothing 6.35 \times 31.8\text{mm}$	15A 250V AC

IP55

CUT-OUT

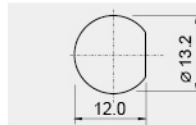

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[R3-9CO](#) [R3-9C](#)