


Rating	300mA
Insulation Resistance	DC 500V 100M ohm Min.
Dielectric Strength	AC 1500V 1 minute
Operation Temperature	-20°C~+80°C
Color	Red

*Material:
 Handle: ABS.
 Clip: Phosphor bronze.
 *Fits O.D. less than $\phi 2\text{mm}$ wire by soldering.

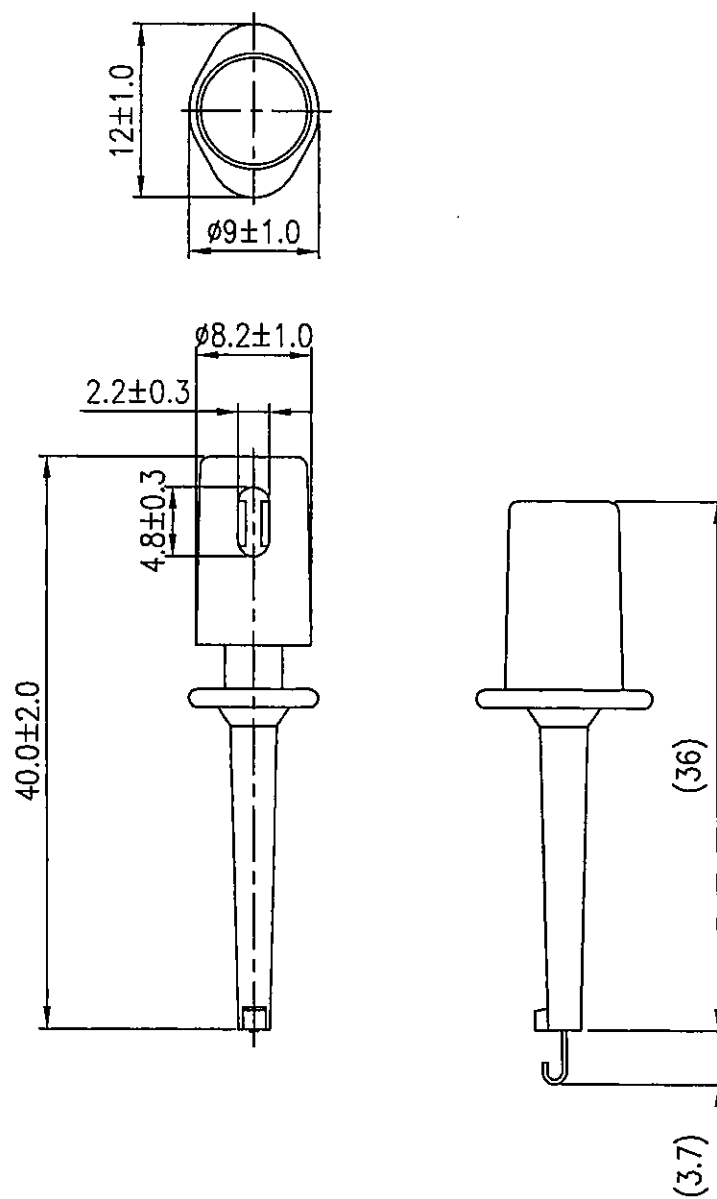

									△
									△
Date	Name		Description						No.
Drawn	Checked	Approved	SCI BOM No.		Model Name	IC CLIP			
曾敏捷	李伟雄	Shin	Customer No.	112-R8-16F-R	Model No.	R8-16F			Rev.
03/17/21	03/17/21	3/17/21	Unit	mm	Shin Chin Industrial Co., Ltd.				X0

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[R8-16F-R](#)