



Wire Nuts

159-1803, 159-1804, 159-2214, 159-2216

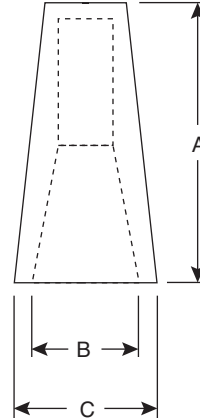

Wire Nuts

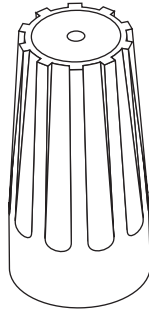

SPECIFICATIONS

Temperature Rating:	105°C
Electrical Rating:	300V
Retaining Spring:	Steel Wire

MOUSER STOCK NO.	Color Coding	AWG Combination		Dimensions: In.		
		Min.	Max.	A	B	C
159-2214	Orange	#20x3	#16x3	.693	.291	.386
159-2216	Gray	#20x1+#22x1	#16x2	.598	.264	.339
159-1803	Yellow	#20x3	#16x3+#18x1	.866	.39	.50
159-1804	Red	#14x1+#18x1	#14x4+#18x1	.965	.433	.551

Date Last Revised: 01-15-19

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300722

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

159-1803, 159-1804, 159-2214, 159-2216

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobiconn:

[159-1803](#) [159-1804](#) [159-2216](#) [159-2214](#)