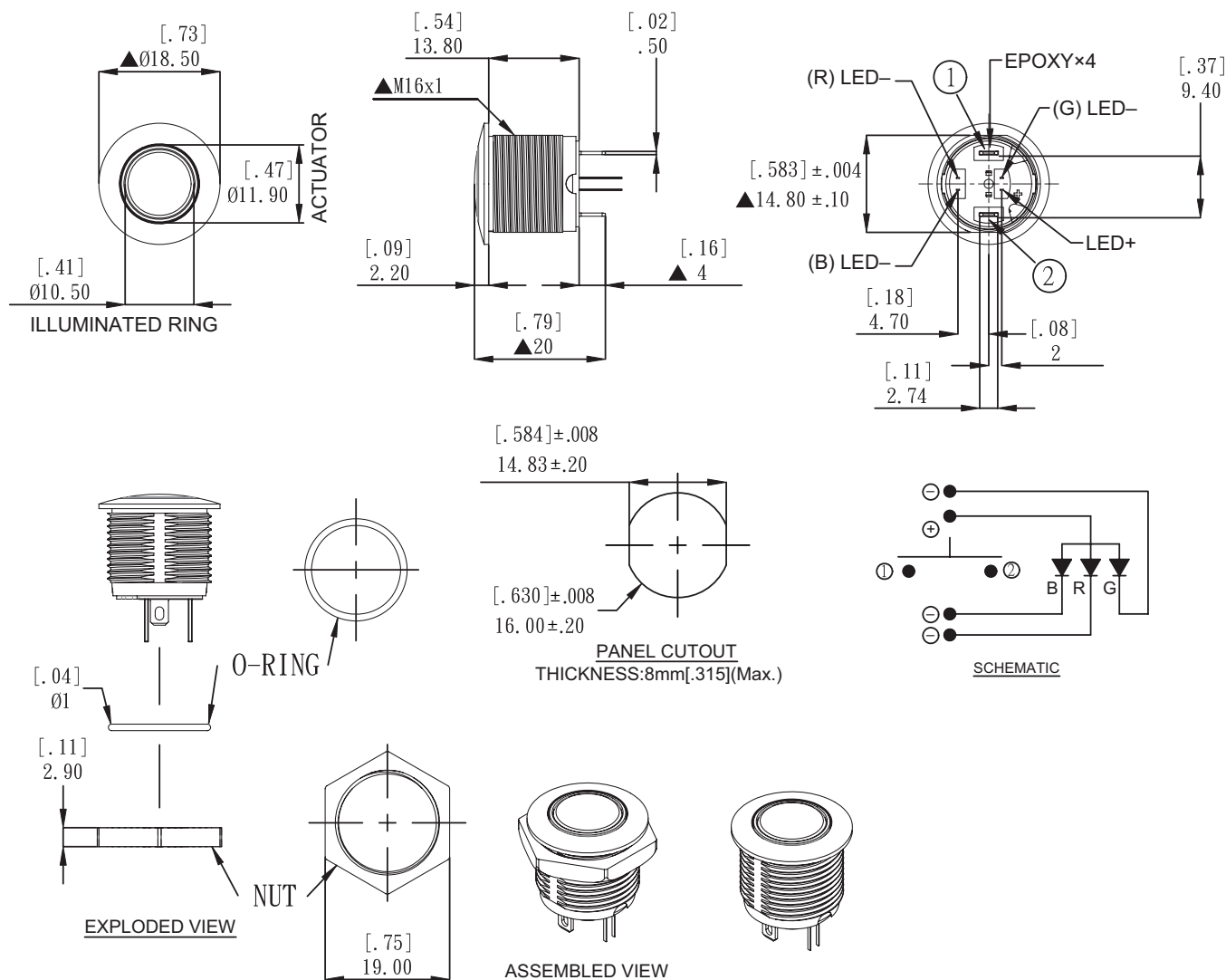


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 2A/36VDC.
- Life: 200,000 Make-And-Break Cycles At Full Load.
- Insulation Resistance: 1,000M Ω Min. at 500VDC
- Dielectric Strength: 2,000 V RMS@ sea level.
- Contact Resistance: 50m Ω Max.

Mechanical Specifications:

- Life: Momentary 1,000,000 Cycles.
- Operating Temperature: -20°C t~+70°C
- Light Type: Ring
- LED Color: Red/Green/Blue

Note:

- RoHS Compliant by Exemption

Illuminated Pushbutton Switch
108-16AR0-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-16AR0-EVX](#)