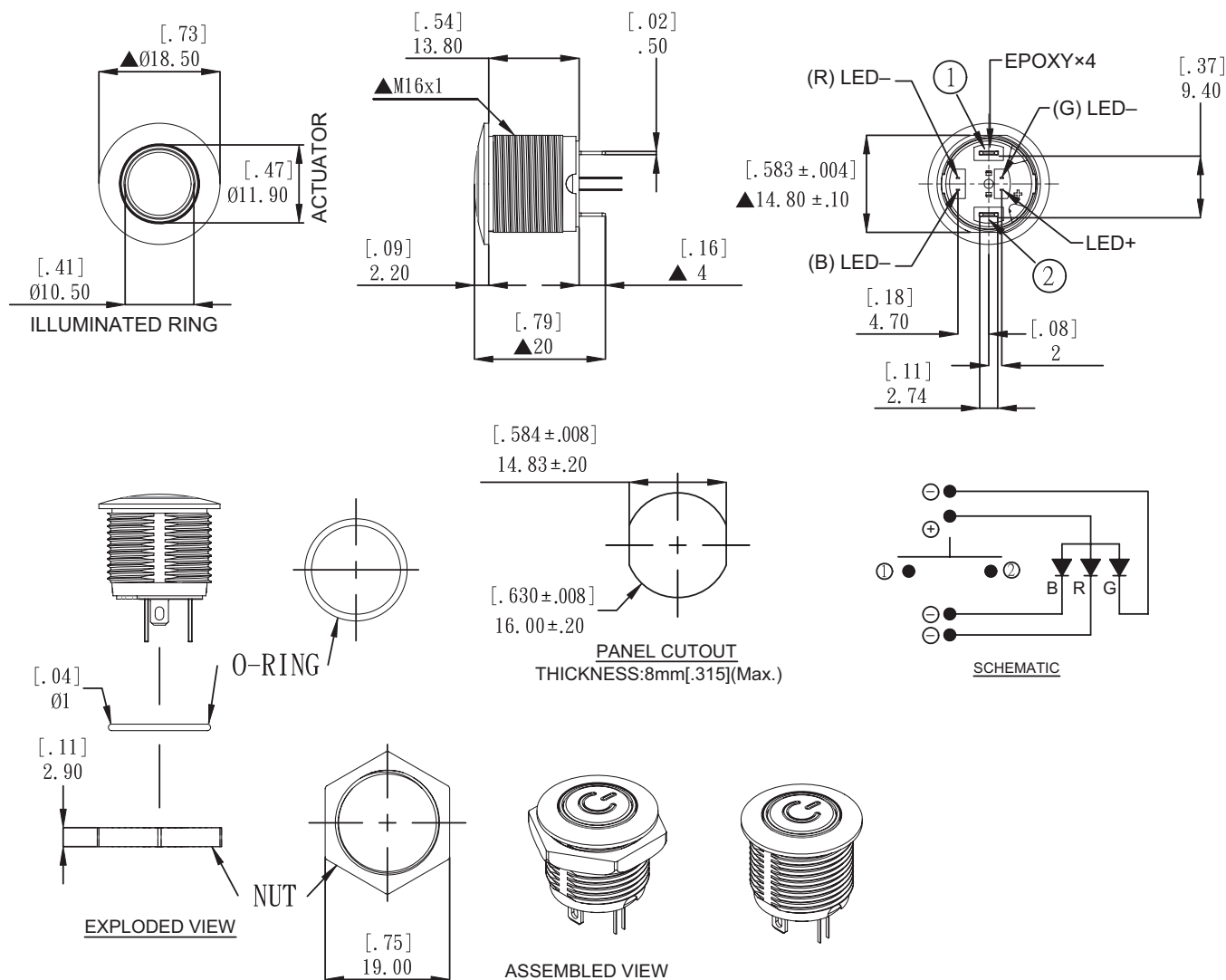


## Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 2A/36VDC.
- Life: 200,000 Make-And-Break Cycles At Full Load.
- Insulation Resistance: 1,000M $\Omega$  Min. at 500VDC
- Dielectric Strength: 2,000 V RMS@ sea level.
- Contact Resistance: 50m $\Omega$  Max.

**Mechanical Specifications:**

- Life: Momentary 1,000,000 Cycles.
- Operating Temperature: -20°C~+70°C
- Light Type: Power Logo
- LED Color: Red/Green/Blue

**Note:**

- RoHS Compliant by Exemption

Illuminated Pushbutton Switch  
108-16BP0-EVX

**Mountain**  
**Switch**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-16BP0-EVX](#)