


Dimensions: mm (in.)

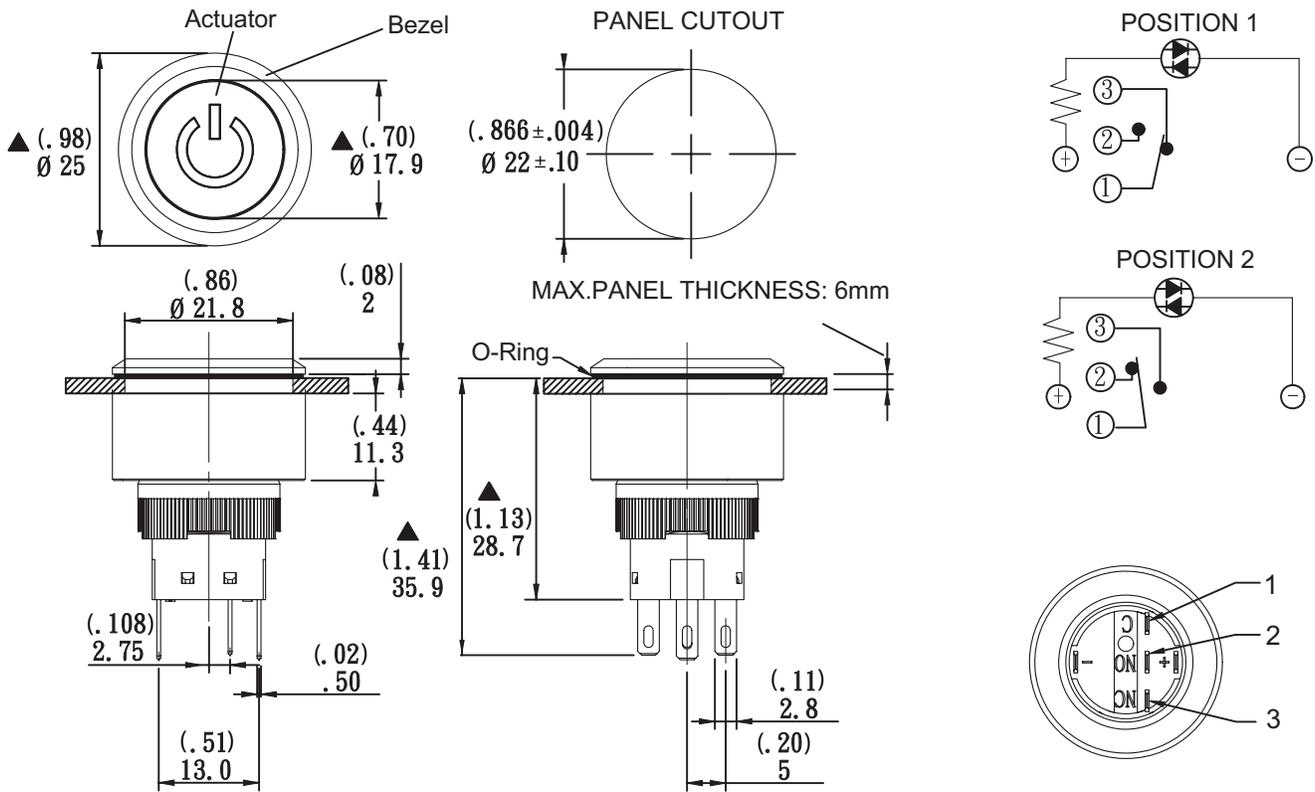

Electrical Specifications:

- Rating: 5A/250VAC. resistive load 3A/250VAC
- Life: 50,000 Make-And-Break Cycles at Full Load.
- Insulation Resistance: 1,000M Ω Min. At 500VDC.
- Dielectric Strength: 2,000V RMS@sea level.
- Contact Resistance: 50m Ω Max. @1A 12VDC(Initial Value)

Mechanical Specifications:

- Life: Self-Lock 500,000
- Operating Temperature: -20°C to 55°C
- Actuator Type: Silver Actuator+Red Power
- LED Color: Red

Note:

- RoHS Compliant

Illuminated Pushbutton Switch
107-KP88-F3-EV

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mountain Switch:](#)

[107-KP88-F3-EV](#)