



Part Number:

254-MS4822-RO

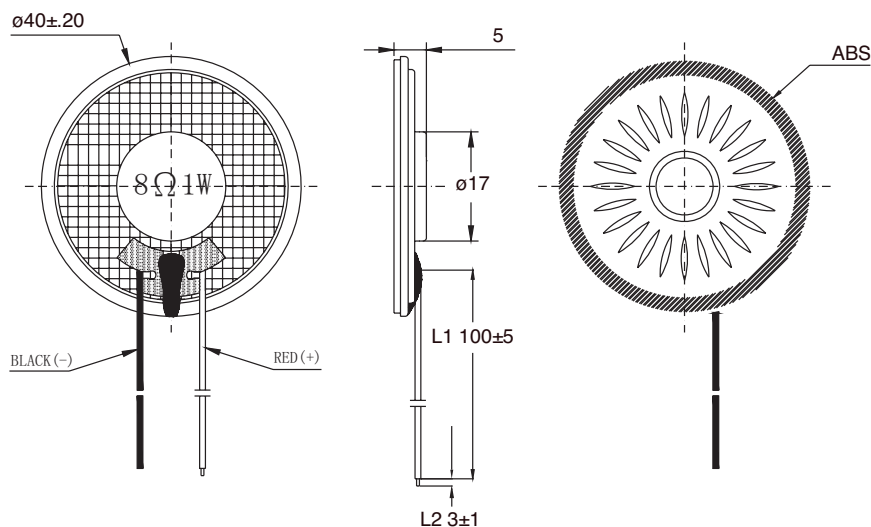

LEAD WIRE:#30AWG

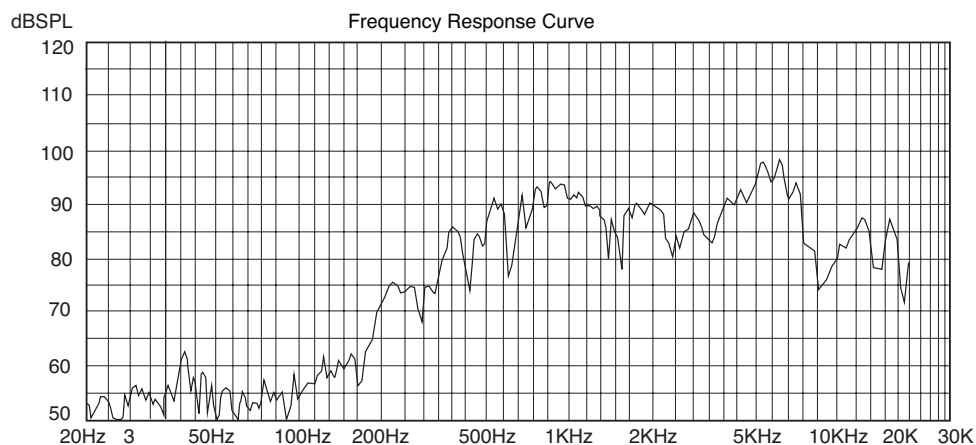

KT-400582

Electrical Specifications:

- Power Rating: Normal 1.0W. Maximum 2.0 W.
- Nominal Impedance: $8\Omega \pm 15\%$ At 1000Hz/1.0V
- Lowest Resonant Frequency: $680 \pm 150\text{Hz}$
- Output Sound Pressure Level (S.P.L.): $89 \pm 3\text{dB}/1.0\text{W}/0.5\text{M}$ Average at 1000, 1200, 1500, 2000Hz
- Frequency Response Range: 350~4,500Hz SPL-10dB

Mechanical Specifications:

- Storage temp: -25°C to $+85^{\circ}\text{C}$
- Operating temp: -25°C to $+85^{\circ}\text{C}$ (Ten Minutes At $+120^{\circ}\text{C}$)

Notes:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-MS4822-RO](#)