


Cable Assemblies 3.5mm

172-7437-E

KOBI CONN

Cable Assemblies 3.5mm

172-7437-E

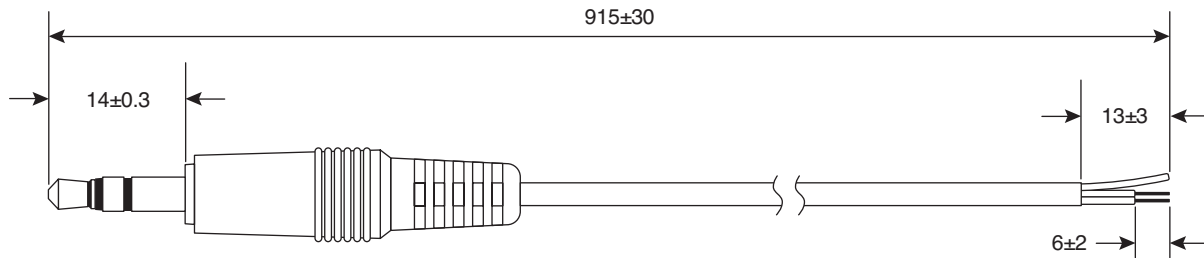

CONNECTION	
P1	COLOR
PLUG TIP	WHITE
RING	RED
SLEEVE	DRAIN

Dimensions: mm

Specifications:	
Operation Temperature:	-10°C - +80°C
Insulation Resistance:	DC/250V 10MΩ Min.
Withstand Voltage:	AC/250V 2mA, for one minute
Tensile Strength:	Overmold to cable jacket shall withstand 3kgf pull min. for one minute.

RoHS Compliant

Date Last Revised: 08/23/19

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301294

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-7437-E](#)