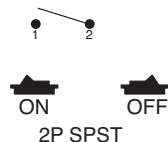
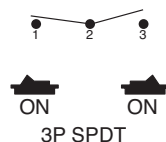


Dimensions: mm (In.)

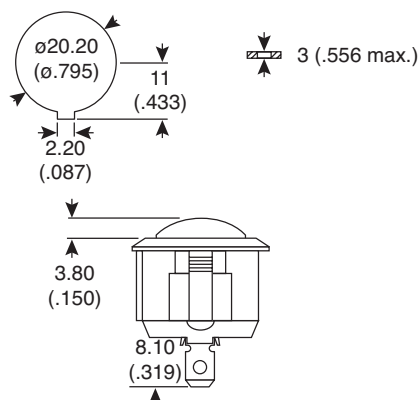
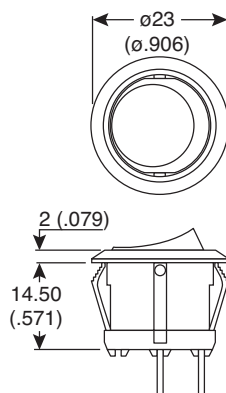
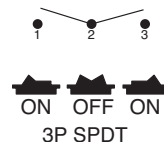
103-R13-112A-02-EV



103-R13-112C-02-EV



103-R13-112D-02-EV

**Electrical Specifications:**

- Rating: 16A/125VAC, 10A/250VAC
- Contact resistance: 50mΩ max.
- Insulation resistance: 500VDC 100MΩ min.
- Dielectric strength: 1500VAC for 1 Minute

Note:

- RoHS Compliant

Rocker Switches

103-R13-112A-02-EV, 103-R13-112C-02-EV, 103-R13-112D-02-EV

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-R13-112D-02-EV](#) [103-R13-112A-02-EV](#) [103-R13-112C-02-EV](#)